



# DANO

120V PENDANTS

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

Cord-hung pendant with European glass shade and inner wood diffuser.

### LAMPING

**LED:** 9W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours. Lamp included. (Additional Color Temperatures available, including 3500°K and 4000°K)

### DIFFUSER

Shade shall be of glass in various decors with inner wood diffuser. 9" Dia. x 13" H

### SUSPENSION

**Cord-hung:** 10' SVT-type cord, complete with 5" decorative sleeve at the socketholder. Jacket coordinates with metal finish. Plated stamped steel construction. Black, Bronze or Satin Nickel. See next page for mulit light options.

### MOUNTING


Installs directly to a 4" octagonal ceiling box. Suitable for sloped ceilings.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only). Consult factory concerning lower wattage labeling for energy requirements.



SMOKE/MEDIUM (DANOSMMD) & CLEAR/NATURAL (DANOCLNA)

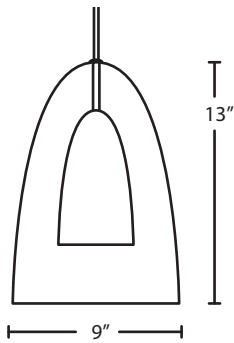

DANOCLMD  
CLEAR/MEDIUM

DANOSMNA  
SMOKE/NATURAL



Project Information:

For ordering information, see next page

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.


REV 5/22



ORDERING:

Table with columns: CONNECTION, GLASS OPTIONS, LAMP OPTIONS, METAL FINISH, OPTIONS. Includes options like 1JC 1 Lt. Dome, 1JT 1 Lt. Flat, DANOCLNA, DANOCLMD, DANOSMNA, DANOSMMD.

Multi light Cord Fixture
J For Multi light Canopy

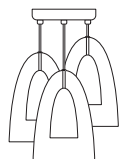


Multilight Canopies Available, see page 11

Ex. 1JT-DANOCLMD-SN
Dano Pendant, Clear/Medium Shade, Satin Nickel Finish, Flat Canopy


MULTIPOINT CANOPY OPTIONS FOR CORD PENDANTS

T33X 3 LIGHT ROUND CANOPY

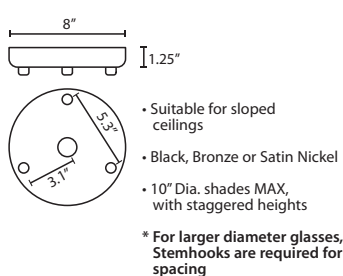


- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
10 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

T33XL 3 LIGHT LARGE ROUND CANOPY

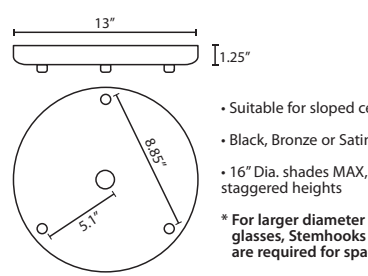


- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
16 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

T36X 6 LIGHT ROUND CANOPY

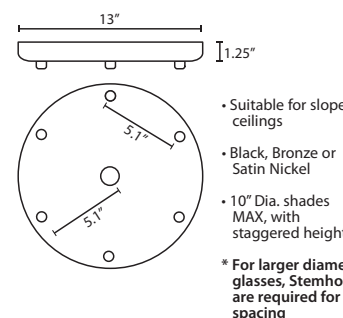


- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
10 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

T39X 9 LIGHT ROUND CANOPY

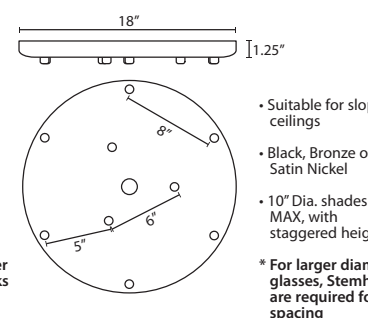


- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
10 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

 T33V 3 LIGHT BAR CANOPY




- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
20 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

 T34V 4 LIGHT BAR CANOPY



- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
20 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing


T37V 7 LIGHT BAR CANOPY

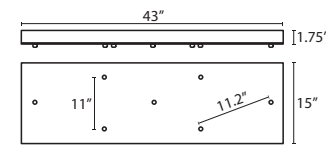

- Suitable for sloped ceilings
Black, Bronze or Satin Nickel
20 inch Dia. shades MAX, with staggered heights
For larger diameter glasses, Stemhooks are required for spacing

PENDANT OPTIONS:

1JT / 1JC / J CORD-HUNG PENDANT

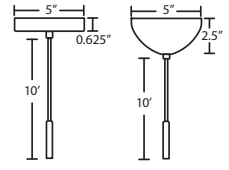

- Flat (1JT) or Dome (1JC) Canopy styles. Dome style allows adjustment without cutting cord.
J option is pendant less canopy for multipoint canopy (options to the right)
Suitable for sloped ceilings
Cord: 10' SVT, 5" sleeve at socketholder
Also available in 15'
Black, Bronze or Satin Nickel
Cord Sleeves are available in 18" lengths

ACCESSORIES:

LONGER CORD LENGTHS:

Longer cord length of 15' available. Add an 'L' to the end of the item number, i.e. 1JC-169707-SN-L.

LOW WATTAGE LABELING:

Incandescent fixture supplied with 16 watt relamp label. Add an 'LW' to the end of the item number, i.e. 1JC-169707-SN-LW.

CORD SLEEVES:

If concealing the cord is desired on a Cord-hung Pendant, order our 0.25" dia. metal sleeves. Each sleeve is 18" long and may be field cut.

- T118-BK Black
T118-BR Bronze
T118-SN Satin Nickel

STEMHOOKS:

Suspension hooks allow cord drops to be placed wherever desired. Suitable for sloped ceilings or for greater multilight spacing

- T103BK Black
T103BR Bronze
T103SN Satin Nickel

HOW TO ORDER A MULTILIGHT FIXTURE

Order your canopy with the selected 120V multi light pendants (indicated by 'B' or 'J' prefix) for the complete fixture:

Example: 1x T33X-SN (3 Light Round Canopy)

- 1x J-DANOCLNA-SN (Dano Pendant in Clear/Natural)
1x J-DANOCLMD-SN (Dano Pendant in Clear/Medium)
1x J-DANOSMNA-SN (Dano Pendant in Smoke/Natural)