



DARCI 16 / 21

WALL SCONCES

ADA

COMPLIANT

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted **ADA-compliant** sconces featuring open-ended handcrafted glass.

LAMPING

Standard: 60W A15 120V incandescent, suitable for dimming, lamp not included. *(Incandescent dimmer is suitable for dimming, not included)*

LED: 5W LED Replaceable source 120V, CL dimmable, 90+ CRI, 3000°K CCT, 550 lumens, 30,000 hours, lamp included.

DIFFUSER

Diffuser shall be handcrafted glass of Opal Matte decor.

Darci 16: 4.75" W x 15.5" H x 3.625" D

Darci 21: 4.75" W x 21.25" H x 3.625" D

CONSTRUCTION

Steel fitter and canopy-cover available with plated finishes. Glass is secured by steel set screws.

METAL FINISH

Decorative metal accents shall be in various finish options.

MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture.

75°C supply wire required for incandescent lamping.

Orient horizontal or vertical, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



DARCI 16 SHOWN IN OPAL MATTE (272507) & DARCI 21 SHOWN IN OPAL MATTE (272607)

For ordering information, see next page


All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18




ORDERING:

Darci 16: #2725

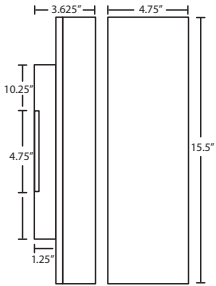

FIXTURE/DECOR	LAMP OPTIONS	METAL FINISH	OPTIONS
272507 Opal Matte	(blank) 2x 60W A15 Incan LED 1x 5W LED 120V	BR Bronze PN Polished Nickel SN Satin Nickel	LW Low Wattage labeling

Darci 21: #2726

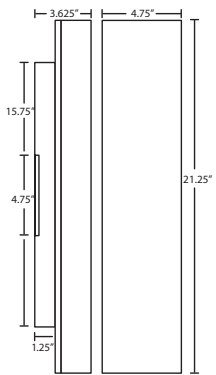

FIXTURE/DECOR	LAMP OPTIONS	METAL FINISH	OPTIONS
272607 Opal Matte	(blank) 3x 60W A15 Incan LED 2x 5W LED 120V	BR Bronze PN Polished Nickel SN Satin Nickel	LW Low Wattage labeling

Ex. 272507-SN
Darci 16 Wall Sconce w/ Opal Matte Glass,
Satin Nickel Finish

Project Information: