



QUAD 10 / 13

METALWORKS OUTDOOR

ADA

COMPLIANT

location:
WET

SPECIFICATIONS:

DESCRIPTION

Our Quad collection is built for outdoor use, but the grid faceplate design allows it to be equally attractive indoors. **ADA-compliant.**

LAMPING

Quad 10: 10W Replaceable source, 120V, dimmable, 90+ CRI, 3000°K CCT, 865 lumens, 25,000 hours, lamp included.

Quad 13: 15W Replaceable source, 120V, dimmable, 90+ CRI, 3000°K CCT, 1550 lumens, 25,000 hours, lamp included.

DIFFUSER

Diffuser shall be handcrafted Opal Matte glass with a grid decorative face plate.

Quad 10: 10" L x 10" H x 2.75" D

Quad 13: 13" L x 13" H x 2.75" D

CONSTRUCTION

Stamped aluminum fitter is powder coated white. Glass is secured by stainless steel set screws.

MOUNTING


Installs directly to a 4" octagonal outlet box. 75°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Wet Locations (interior or exterior use).



OPAL/ BLACK (QUAD10) & OPAL/SILVER (QUAD13)

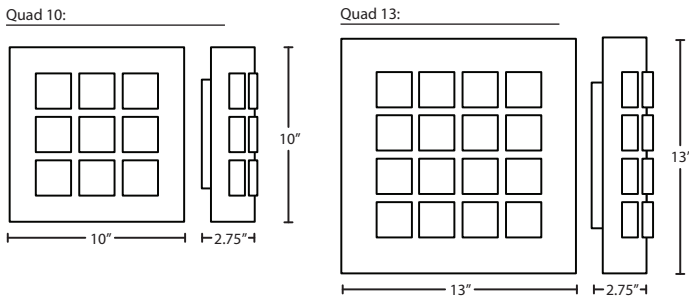

QUAD10-LED-BR
OPAL/BRONZE

QUAD10-LED-BK
OPAL/BLACK



FIXTURE	LAMP OPTIONS	METAL FINISH
QUAD10 10" Opal Matte	LED 10W LED 865 lumens 3000K	BK Black BR Bronze SL Silver

FIXTURE	LAMP OPTIONS	METAL FINISH
QUAD13 13" Opal Matte	LED 15W LED 1550 lumens 3000K	BK Black BR Bronze SL Silver

Ex. QUAD13-LED-SL

Quad 13 LED Outdoor Sconce, Opal Matte Shade, Silver Finish

Project Information:

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 3/22