



SCALA 13 / 20 / 28 / 40

METALWORKS OUTDOOR

location:
WET

SPECIFICATIONS:

DESCRIPTION

Wall-mounted heavy-gauge aluminum sconce. Four sizes available.

LAMPING

Standard: 60W A19 120V incandescent, lamp not included.

LED: 8W Replaceable LED source, 120V, dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours, lamp included.

LED: 11W Replaceable LED source, 120V, dimmable, 80+ CRI, 3000°K CCT, 1100 lumens, 30,000 hours, lamp included. (Scala 40 only)

DIFFUSER

White impact-resistant Acrylic diffuser available in all sizes.
Satin White glass diffuser option on Scala13 and Scala20 only.

CONSTRUCTION

.080" aluminum housing and faceplate, with a bronze, black or silver powder coating. Faceplate is secured by stainless steel screws.


MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture.
75°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Wet Locations.
May be used in Interior or Exterior applications.

METALWORKS LUMINAIRES ARE ASSEMBLED WITH SHEET METAL FABRICATED AND POWDER COATED IN THE USA.

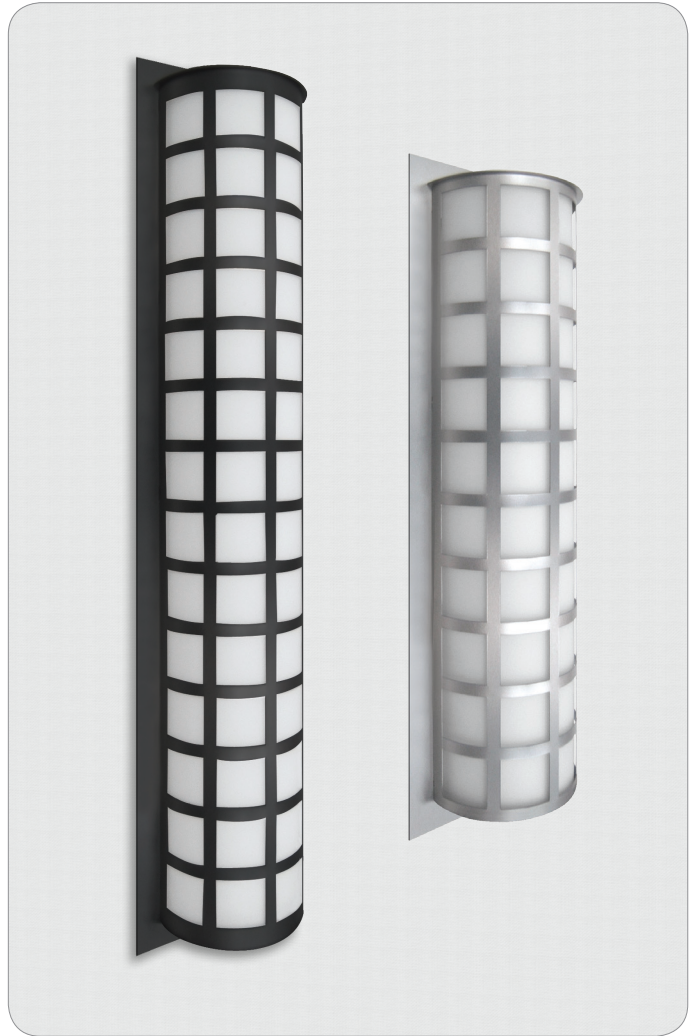

SCALA 40 SHOWN IN BLACK WITH WHITE ACRYLIC (SCALA40-WA-BK) & SCALA 28 SHOWN IN WHITE ACRYLIC (SCALA28-WA-SL)

SCALA13
BRONZE



SCALA13
SILVER



SCALA20
BRONZE



SCALA20
SILVER



For ordering information, see next page


All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18




ORDERING:

Scala 13:

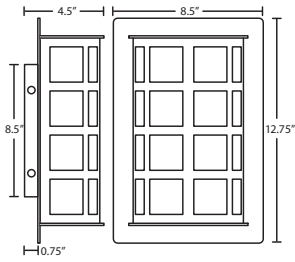


Scala 20:

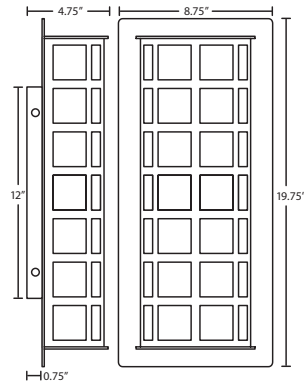


FIXTURE	DIFFUSER	LAMP OPTIONS	METAL FINISH
SCALA13 Sconce	SW Satin White Glass WA White Acrylic	(blank) 1x 60W A19 Incan LED 1x 8W LED 120V, dimnable	BK Black BR Bronze SL Silver

FIXTURE	DIFFUSER	LAMP OPTIONS	METAL FINISH
SCALA20 Sconce	SW Satin White Glass WA White Acrylic	(blank) 2x 60W A19 Incan LED 2x 8W LED 120V, dimnable	BK Black BR Bronze SL Silver

Scala 28:

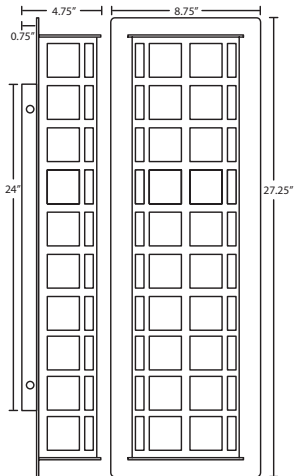

Scala 40:

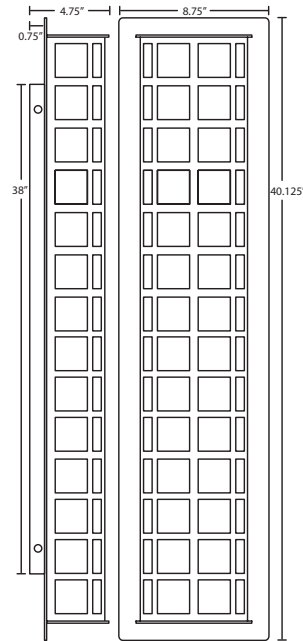

FIXTURE	DIFFUSER	LAMP OPTIONS	METAL FINISH
SCALA28 Sconce	WA White Acrylic	(blank) 3x 60W A19 Incan LED 3x 8W LED 120V, dimnable	BK Black BR Bronze SL Silver

FIXTURE	DIFFUSER	LAMP OPTIONS	METAL FINISH
SCALA40 Sconce	WA White Acrylic	(blank) 3x 60W A19 Incan LED 3x 11W LED 120V, dimnable	BK Black BR Bronze SL Silver

Ex. SCALA28-SW-SL
3 Lt. Scala 28 Sconce w/ White Acrylic,
Silver Finish

Project Information: