



WAVE 12 / 15

FLUSH MOUNT CEILING

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Flush-mounted ceiling luminaires, featuring handcrafted glass. Two sizes available.

LAMPING

Standard: A19 120V incandescent, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED Filament: 7W Replaceable LED Filament lamp, 120V, CL dimmable, 80+CRI, 3000°K CCT, 800 lumens, 15,000 hours, lamp included.

DIFFUSER

Handcrafted glass diffuser is available in various decors.

Wave 10 #9092XX: 11.75" Dia. x 6.25" H

Wave 12 #9063XX: 15" Dia. x 7" H

CONSTRUCTION

Glass diffuser is secured to fitter with "twist & lock" bayonet action. Stamped aluminum fitter.

MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture. 90°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



WAVE 15 CEILING SHOWN IN CLEAR (906361C)



Twist and lock bayonet glass

CLEAR

SMOKE



For ordering information, see next page


All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 8/21




ORDERING:

Wave 12: #9062

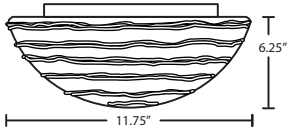

FIXTURE/DECOR	LAMP OPTIONS	OPTIONS
906202C 11.75" Dia. Smoke	(blank) 1x 100W A19 Clear Incan	LW Low Wattage
906261C 11.75" Dia. Clear	EDIL 1x 7W LED Filament	labeling

Wave 15: #9063

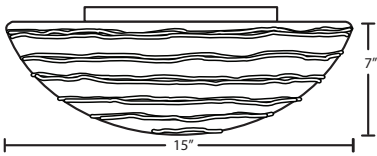

FIXTURE/DECOR	LAMP OPTIONS	OPTIONS
906302C 15.0" Dia. Smoke	(blank) 3x 60W A19 Clear Incan	LW Low Wattage
906361C 15.0" Dia. Clear	EDIL 3x 7W LED Filament	labeling

Ex. 906202C
Wave 12 Ceiling w/ Smoke Glass

Project Information: