

Lock'N-Pin 3/4" Pin



#1 supplier of 3/4" pin seating hardware. Here's why:

- The 3/4" system gives you outstanding economical performance
- The design is proven by decades of experience
- Posts are available as fixed, manually adjustable or power adjustable
- Seat mounts, posts and bases are available in steel, aluminum or stainless steel

The Difference

- The patented Lock'N-Pin system leads the industry in safety
- Lock'N-Pin prevents unintentional detachment for seat mounts, posts and bases
- Lock'N-Pin products exceed ABYC Standard H31.6.1

Not recommended to interchange with other manufacturers' products

Lock'N-Pin 3/4" Pedestal Packages

Includes Brushed aluminum post, black E-coated seat mount with Spring & Base Plate.

Description	Post	Base 7"x7"	ABYC Code	Post	Seat Mount	Base Plate	OEM Part #	Part #
Non-Threaded	11"	SS Base Plate	B	2114	1002	67739	—	97739
Threaded	11"	SS Base Plate	B	2114-T	1002	67739-T	—	97739-T
Threaded	13"	SS Base Plate	B	2134-T	1002	67739-T	—	977339-T
Brushed Aluminum Finish Kit, Non-Threaded	11"	Aluminum Base Plate	B	2114	1002	67749	—	97749-7
Camouflage Finish Kit, Non-Threaded	11"	Aluminum Base Plate	B	2114	1002	67749	—	97749C-7




97749-7

97749C-7

Lock'N-Pin 3/4" Pin Seat Mounts

Description	Tilt	Pin	ABYC Code	Installed Height	OEM Part #	Part #
Zinc-plated	3°	2-3/4" Steel Pin w / Spring	B	2"	—	SP-1002
Black E-Coated	3°	2-3/4" Steel Pin w / Spring	B	2"	1002	—
Black E-Coated	3°	2-1/2" Steel Pin	B	1"	1002-S	—
All Stainless Steel	3°	2-3/4" Stainless Steel Pin	B	1"	1002-SS	—

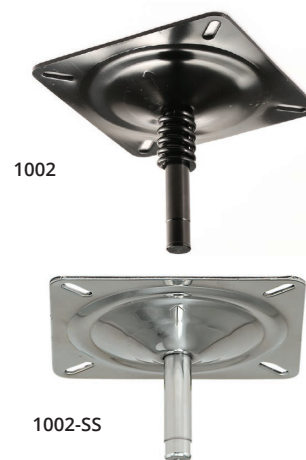


1002

1002-SS

075 Pedestal Kits

Take the confusion out of buying pedestals with these convenient 3/4" pin kits. Kits include seat mount, post and 7" x 7" base. Simply choose the appropriate post height and finish. Attwood's 3/4" pin kit is corrosion resistant, features a 360 degree swivel, a shock absorbing spring, and a removable pin post. Lock 'N' Pin technology features an all steel pin, increasing pedestal strength and durability. Available in brushed aluminum or Realtree MAX-4 camouflage.

Description	ABYC Code	OEM Part #	Part #
Base Plate: 7" x 7", Seat Mount 5-1/4" X 5-1/4" on Center			
Add 3" to post height to get total height, measured from deck to seat			
13" Brushed Aluminum Post	B	—	97750-7
13" Realtree MAX-4 Camouflage Post	B	—	97750C-7

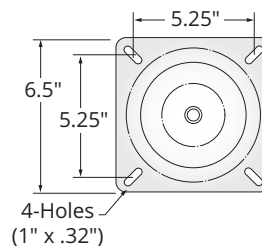

B (Not to be used at the helm/driver position)

See page 184 for ABYC Requirements