




SKU # BALLAST-DIGITAL

Part # 1001108

Description

Discontinued - Superseded by Part# BALLAST-DIGITALv2

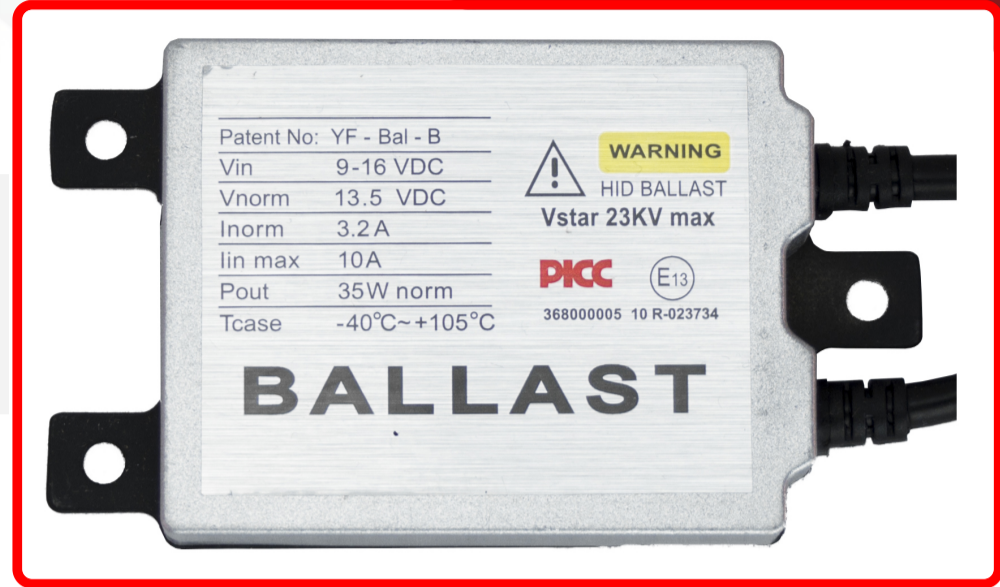

Categories HID & LED Headlights, HID Headlight Conversions

Sub-Categories HID Ballast and Bulb Parts, HID Ballasts

UPC 811712027793

Unit of Measure EA

Related Skus:

Cross Sell Skus:

Condition

New

Manufacturer

Race Sport Lighting

EZ Category

Est. Labor

Hours

Harmonization Code

8512.20.2080

Universal

YES

Life Expectancy

Gross Weight

1.40

Width

3.50

SEMA Product

High Intensity Discharge Lighting Ballast

Part Type ID

15962

Net Weight

1.40

Height

1.75

Reverse Polarity

High Intensity Discharge Lighting Ballast

Operating Voltage

Current Draw

DIM Weight

0.44

Depth

10.00

Wattage

35-Watts

Chip Type

N/A

IP Rating

IP67

LUX

N/A

Kelvin (ColorTemperature)

N/A

Universal or Vehicle Specific

Universal

Made In

China

Warranty

1 year

Lumens

N/A

Beam Pattern

N/A

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov