



SKU # MSUWUS60RGB

Part # 1006990

Description

NEW - HydroBLAST Ultra Slim 2-POD Underwater 60-Watt LED Lighting System - Marine 316 Stainless Steel - RGB Multi-Color

Categories Marine Sport Lighting

Sub-Categories HydroBLAST Underwater LED

UPC 817999026382

Unit of Measure EA

Related Skus:

MSUWBTC12V, MSUWRCC12V

Cross Sell Skus:

MS-27RGB,MSUWL120RGB,MSUWL180RGB

Condition

New

Manufacturer

Marine Sport Lighting

EZ Category

HydroBLAST Marine LED

Harmonization Code

8512.20.2080

Universal

YES

Life Expectancy

50,000 hours

SEMA Product

Marine All-Around Light

Part Type ID 57170

Reverse Polarity

Marine All-Around Light

Operating Voltage

9-15VDC

Current Draw

3.9A

Wattage

60-Watts

Chip Type

CREE

IP Rating

IP68

LUX

Kelvin (ColorTemperature)

RGB

Universal or Vehicle Specific

Universal

Made In

China

Warranty


2 year

Lumens

528-2,750lm

Beam Pattern

Flood

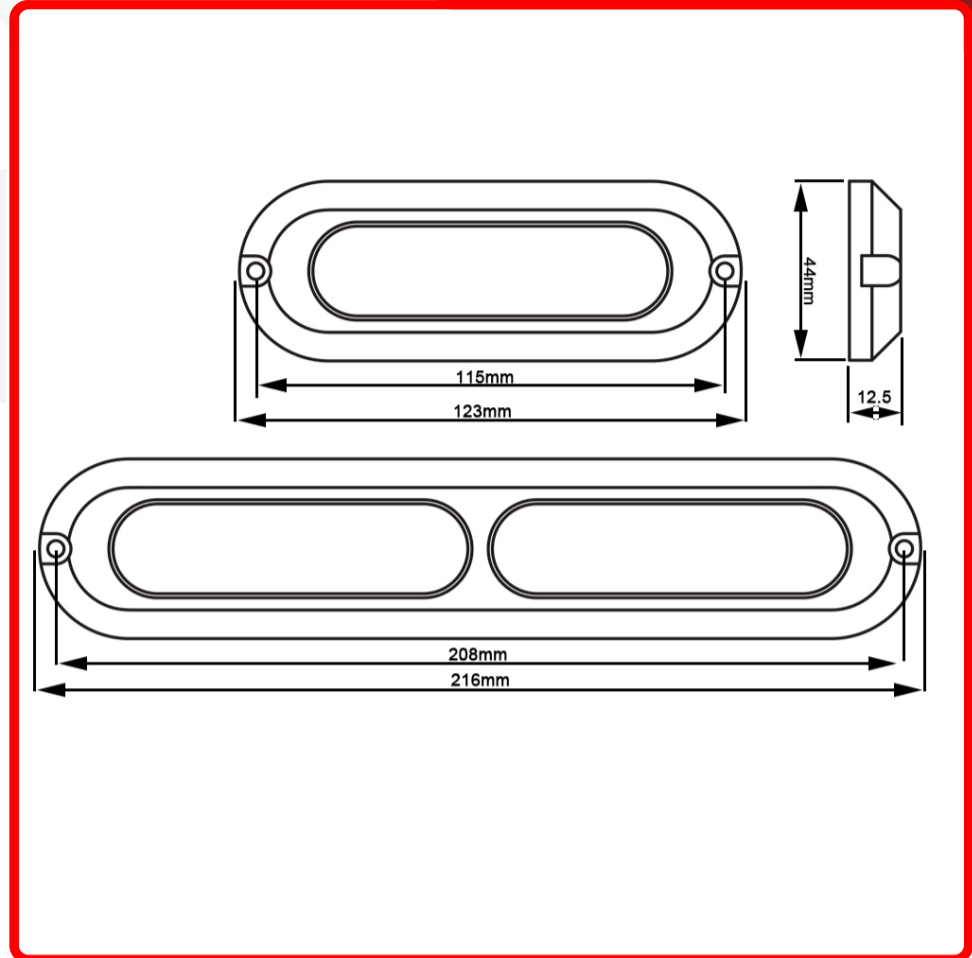

Product Information

Marine 316 Stainless Steel - RGB Multi-Color -input voltage 9-15VDC -current draw 3.3A@13.5VDC -total power consumption 44.5W@13.5VDC -316L Marine Grade Stainless Steel -Poly-carbonate Lens -waterproof IP68 - comes with 5FT wire (18AWG) Requires RGB control panel input, or pairs with our RF (MSUWRCC12V) or Bluetooth APP (MSUWBTC12V) controllers.

HydroBLAST series by Marine Sport Lighting



Est. Labor

1 Hours

Gross Weight

1.00

Width

11.00

Net Weight

1.00

Height

2.50

DIM Weight

0.64

Depth

3.25

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

www.racesportinc.com