




SKU # RSUBGC-LED

Part # 1005415

Description

48in Ultra Bright LED Ground Clearance Light for Trucks (Pair) - USA Made Race Sport Lighting

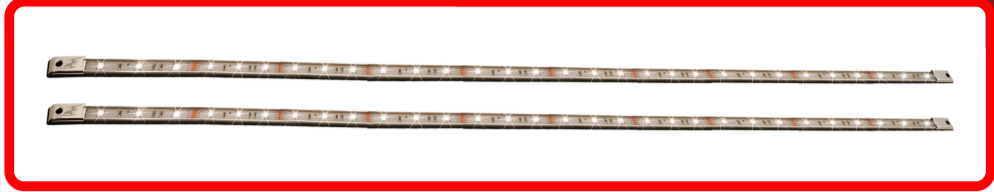

Product Information

Race Sport Lighting's ground clearance lights are an intense lighting solution for undercarriage lighting on your truck. This pair of ultra bright bars utilize a series of height power white 5050 LEDs. IP67 Water-Resistant rated, these bars typically mount underneath the vehicles to add additional enter and exit lighting under and around your vehicle at night. • Includes (2) 48" under-door channels • 30 LEDs per meter (1 1/4" spacing) • 120° light pattern, ensuring overall light coverage • 3M adhesive backing for a secure application • Long life: 20,000 hours • 1 Year Warranty

Categories Auto Interior & Exterior, Interior/Exterior Accent LED

Sub-Categories LED Accent Bars, Ultra Series Accent Bars

UPC 814843026833

Unit of Measure PR

Related Skus:

Cross Sell Skus:

Condition

New

Manufacturer

Race Sport Lighting

EZ Category

LED Accent Lighting

Harmonization Code

8512.20.2080

Universal

YES

Life Expectancy

Est. Labor

Hours

Gross Weight

0.12

Width

4.00

Net Weight

0.12

Height

48.00

DIM Weight

0.69

Depth

0.50

SEMA Product Courtesy Light

Part Type ID 10351

Reverse Polarity

Courtesy Light

Operating Voltage

Current Draw

Wattage

Chip Type

IP Rating

LUX

Kelvin (ColorTemperature)

White

Universal or Vehicle Specific

Universal

Made In

China

Warranty

1 year

Lumens

Beam

Pattern

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

www.racesportinc.com