




SKU # RS-POD5050-15FT-RGB

Part # 1004765

Description

15ft 30-Module LED Pod Strip Light Kit (RGB Multi-Color) with 5050 LED technology - Professional Grade

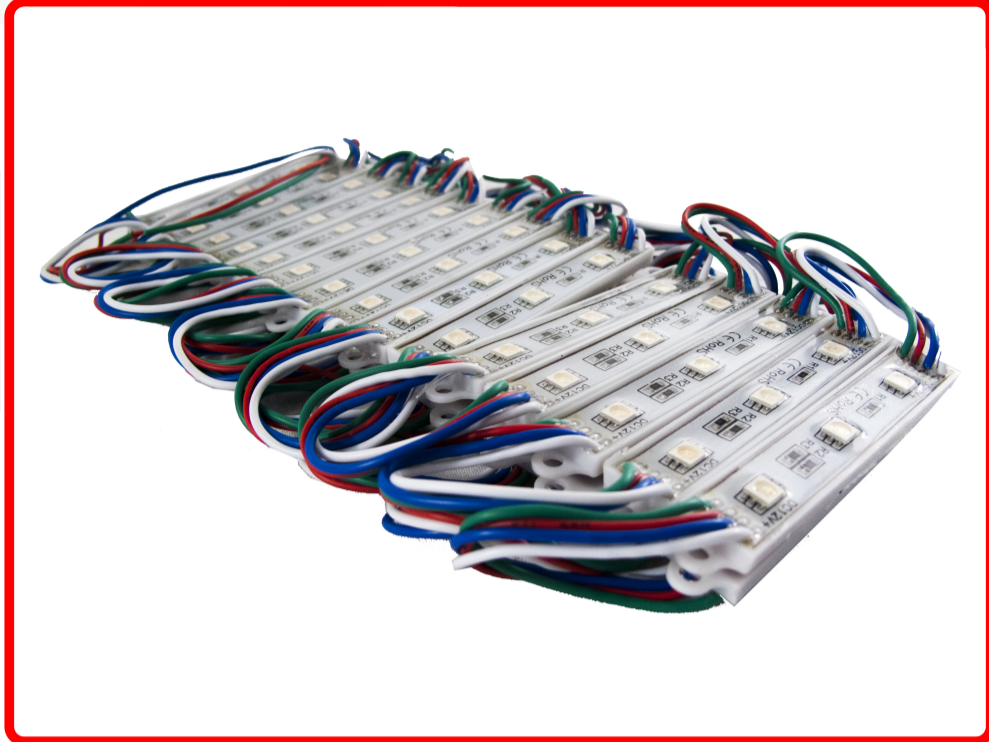

Categories

Powersports, Auto Interior & Exterior, Marine, Marine, LED POD Strip Lighting

Sub-Categories

Professional Grade 5050 POD Strip Lighting, LED Tape & POD strips, LED Accent Lighting Interior, LED Pod Strip Lighting, Pod Strip Lighting Kits

UPC 812867021599

Unit of Measure EA

Related Skus:

Cross Sell Skus:

Condition

New

Manufacturer

Race Sport Lighting

EZ Category

POD Strip Lighting

Harmonization Code

8512.20.2080

Universal

YES

Life Expectancy

SEMA Product Auxiliary Light

Part Type ID 1005

Reverse Polarity

Auxiliary Light

Operating Voltage

Current Draw

Wattage

Chip Type

IP Rating

LUX

Kelvin (ColorTemperature)

RGB

Universal or Vehicle Specific

Universal

Made In

China

Warranty

1 year

Lumens

Beam Pattern

Linear

Product Information

- Custom LED pod strips can be used to accent store windows, vehicles, and countless other applications
- Uses high quality 5050 LEDs for brighter, longer lasting quality and colors
- Completely waterproof design
- ROHS compliant
- 3 diodes per pod
- Mounts with 3M adhesive tape or screws
- 2-wire power and ground setup
- 1 Year Warranty

Est. Labor

Hours

Gross Weight

0.50

Width

6.00

Net Weight

0.50

Height

10.00

DIM Weight

0.65

Depth

1.50

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov