




SKU # RS-U30LEDC25.5-W

Part # 1004853

Description

25.5 inch White LED Ultra Bright Accent Weatherproof Light Bar Strip with Aluminum Mounting Channel Ultra Series - USA Made Race Sport Lighting

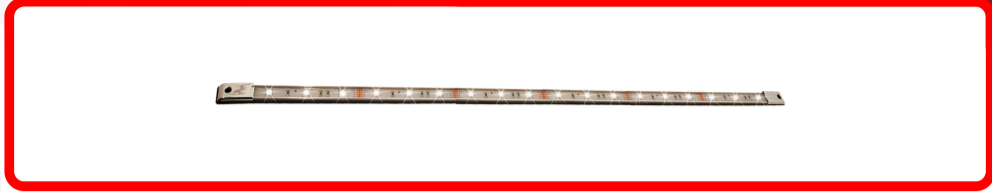

Product Information

Race Sport Lighting's Ultra Series LED accent bars are a durable, ultra-bright lighting solution, ready to take a beating in any exterior automotive lighting application • 25.5" Long • Polished aluminum channel with chrome tips • Great for all exterior applications like truck bed lighting or courtesy lights • Mounts with 3M tape or screw-mount metal channel • IP68 Waterproof Rated • 30 LEDs/m (1 1/4" spacing) or 60 LEDs/m (5/8" spacing) • High lumen output with low heat • Wide dispersion of light • 1 Year Warranty

Categories Auto Interior & Exterior, Interior/Exterior Accent LED

Sub-Categories LED Accent Bars, Ultra Series Accent Bars

UPC 811712021012

Unit of Measure EA

Related Skus:

Cross Sell Skus:

Condition

New

Manufacturer

Race Sport Lighting

EZ Category

LED Accent Lighting

Harmonization Code

8512.20.2080

Universal

YES

Life Expectancy

Est. Labor

Hours

Gross Weight

0.20

Width

4.00

Net Weight

0.20

Height

27.75

DIM Weight

0.20

Depth

0.25

SEMA Product Auxiliary Light

Part Type ID 1005

Reverse Polarity

Auxiliary Light

Operating Voltage

Current Draw

Wattage

Chip Type

IP Rating

LUX

Kelvin (ColorTemperature)

White

Universal or Vehicle Specific

Universal

Made In

USA

Warranty

1 year

Lumens

Beam Pattern

Linear

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

www.racesportinc.com