

客户料号:MD15ARC13-240BK

产品图号:

版次

A/0


详细描述

变更日期

变更者

20FT

6100 ± 70

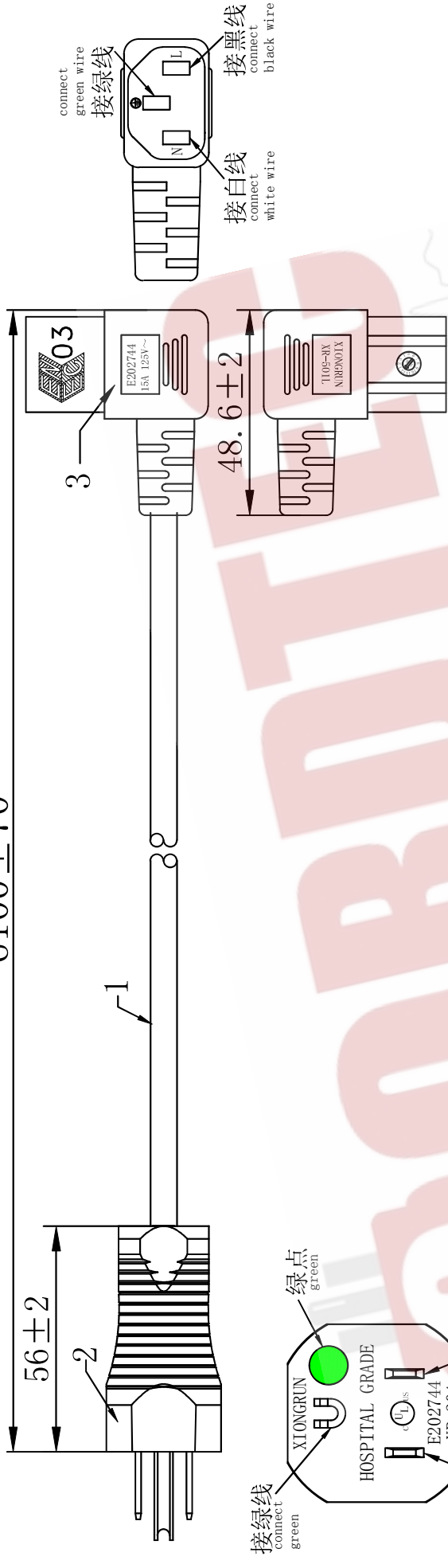

技术要求:requirement:

- 1: 耐压测试:外高压4200V/S;内高压2500V/S;  
Dielectric voltage :between jacket and conductors 4200V/S  
between conductors 2500V/S
- 2: 绝缘阻抗不小于100兆欧。  
Insulation resistance 100MΩ.
- 3:100%导通OK。  
Continuity of lead 100% OK.
- 4 符合ROHS。  
RoHS COMPLIANT.

**CORDTEC POWER CORPORATION**  
**CONFIRMED**

2023.02.2  
ChenTony

**CORDTEC**  
POWER CORPORATION

NO.	DESCRIPTION	QTY	unit
3	品字尾插座C13 (XR-501L) COLOR: 黑色black, PVC	1	EA
2	医疗插 (XR-304-1) HOSPITAL GRADE, COLOR: 999透明色transparent, PVC	1	EA
1	SJTW 14AWGX3C 105°C, COLOR: 黑色black, 裁线长: L=6100mm.	1	EA

AC Connectors of Cordtec Power Corp  
 Main: 1-414-434-2220 Fax: 1-414-323-8386 Text: 1-414-323-3240  
 Email: Info@CordtecPower.com  
 Website: CordtecPower.com/ ACWORKS.com