


CUSTOMER:	P/N: MD195-AL	REV.	APPROVED BY:
REVISIONS	DESCRIPTION	DATE	
REV. A			
REV. B			
REV. C			


**NOTES:**

1. Total Length: 6925mm (Estimate)
2. Wire PVC elastic material (soft PVC)
3. RoHS shown on the carton

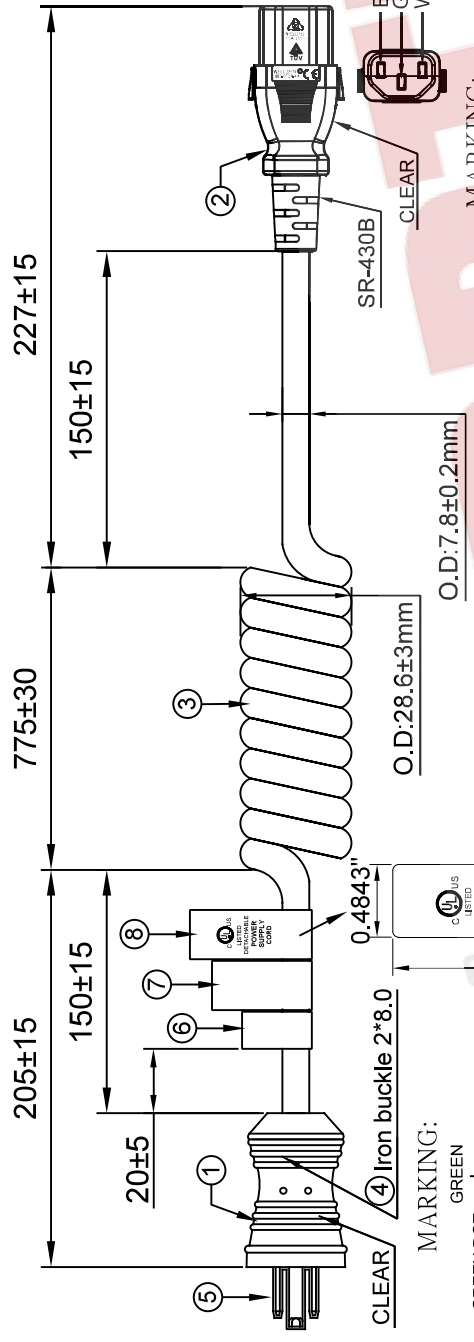

**CORDTEC POWER CORPORATION**  
**CONFIRMED**  
 LABEL  
 2023.03.20  
 Chen Tony

**MARKING:**

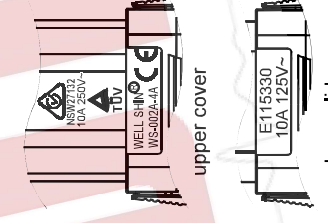

1 PCS INTO THE BAG

Maximum 1250W 10A 125V~	Maximum 1250W 10A 125V~	20
		50

⑦ Hosp. Grade label

35	30	35
GROUNDING RELIABILITY CAN ONLY BE ACHIEVED WHEN THIS EQUIPMENT IS CONNECTED TO A RECEPTACLE MARKED "HOSPITAL GRADE"		UNE FIBRILLE DE MISE EN TERRE PEUT ÊTRE RÉALISÉE UNiquement LORSQUE L'ÉQUIPEMENT EST CONNECTÉ À UNE PRISE FIBRILLE MARQUÉE "CLASSE HÔPITAL"

ITEM	DESCRIPTION	COLOR	Q'TY
⑨	PE bag 340*340*0.04mm	CLEAR	1
⑧	UL Laser label	---	1
⑦	Hosp. Grade label	---	1
⑥	LABEL	---	1
⑤	Plastic cap	WHITE	1
④	Iron buckle 2*8.0mm (Factory material number: FEA2080HS)	---	1
③	SJTW 18AWG*3C 105°C APPROVAL : UL,CSA	GREY GY-3483 Pantone Wm-GY2	1
②	WS-002A-4A 10 (A) 125 (V) APPROVAL : UL,CUL,SAA,TUV,CE	CLEAR	1
①	WS-001H (5-15P) 10 (A) 125 (V) APPROVAL : UL,CUL	CLEAR	1



**AC Connectors of Cordtec Power Corp**  
 Main: 1-414-434-2220 Fax: 1-414-323-8386 Text: 1-414-323-3240  
 Email: Info@CordtecPower.com  
 Website: CordtecPower.com/ ACWORKS.com

SIGNATURE	
SAFETY ENGINEER:	
MANAGER BY:	
CHECKED BY:	
DRAWN BY:	

