

I 180 Drawer Slide Spec Sheet



Mounting: Side mount.

Side Clearance: 12.8mm plus 0.8mm, minus 0" each side.

Height: 1- 27/32"(46.7mm)

Loading: 130 pound class.


Size: 12", 14", 16", 18", 20", 22", 24", 26", 28"

Feature: 32mm hole pattern. Simple access mounting on drawer and cabinet members. Breathing tabs self adjust to side clearance. Hold/close function. Lever disconnect for drawer removal.

Finish: Zinc plated.

Packing: 15 pairs individually poly-packaged, no screws.

Option: Black zinc plated, Interlock, 1" over-travel.

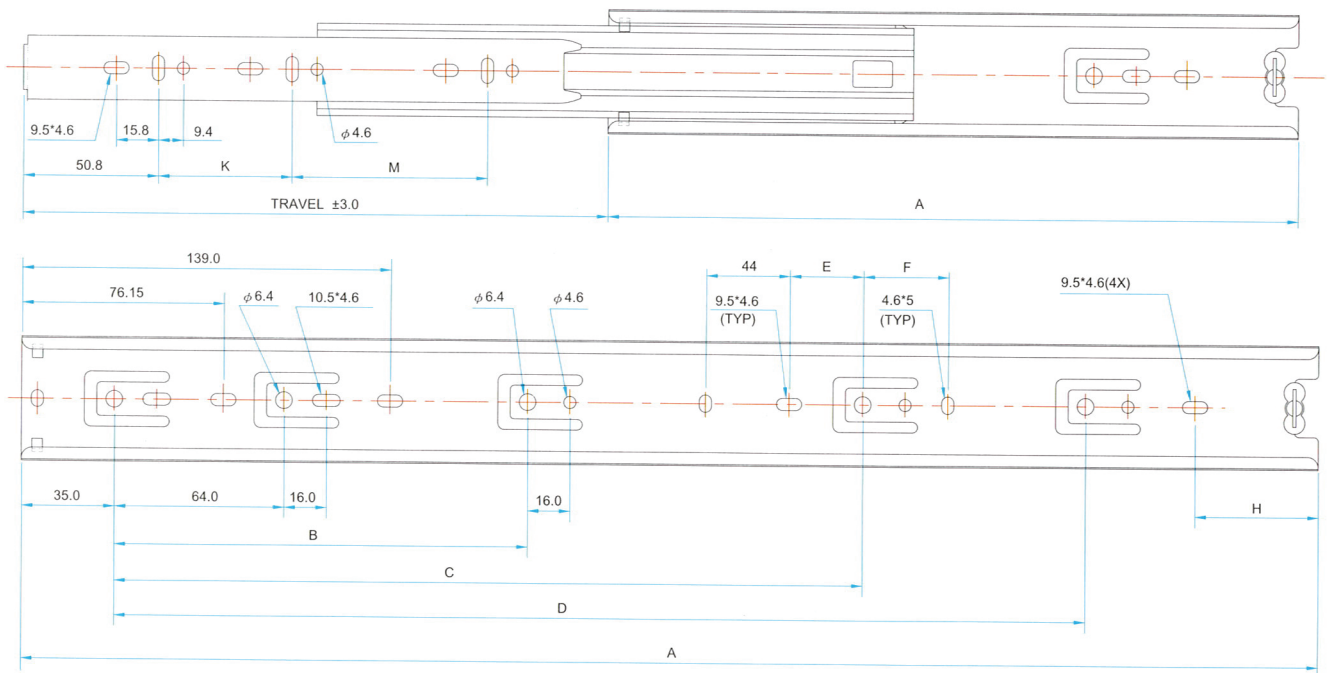

SIZE (IN)	TRAVEL (mm)	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	F (mm)	H (mm)	K (mm)	M (mm)
12	304.8	304.8	224.0						96.0	128.0
14	355.6	355.6	224.0					46.6	128.0	128.0
16	406.4	406.4	224.0	288.0				33.4	160.0	160.0
18	457.2	457.2	224.0	352.0		25.45	32.15		160.0	192.0
20	508.0	508.0	224.0	352.0	416.0	25.45	32.15		192.0	224.0
22	558.8	558.8	224.0	352.0	416.0	25.45	32.15	57.8	224.0	256.0
24	609.6	609.6	224.0	352.0	480.0	25.45	32.15	44.8	256.0	256.0
24	660.4	660.4	224.0	352.0	544.0	25.45	32.15		256.0	320.0
24	711.2	711.2	224.0	352.0	544.0	25.45	32.15	82.2	256.0	352.0

