

NJ-31733



Features


- ▶ 1" over travel
- ▶ Side mount
- ▶ Height: 1-13/16" (45.7 mm)
- ▶ Side spacing:
1/2" (+ 1/32" - 0")
12.7 mm (+ 0.38 mm - 0 mm)
- ▶ Load rating: 100 lbs (22" length)
- ▶ Electro zinc finish (black available)
- ▶ Screw mounting system
32 mm compatible

- ▶ Lengths: 10" - 28"
- ▶ Packaging: 10 pair per carton
- ▶ Easy access window to reach hole on cabinet member in closed position
- ▶ Breather tab self adjustment to accommodate variation in side clearance

Applications

- ▶ Commercial furniture
- ▶ Bedroom furniture
- ▶ Office furniture
- ▶ Kitchen cabinets

Dimensions

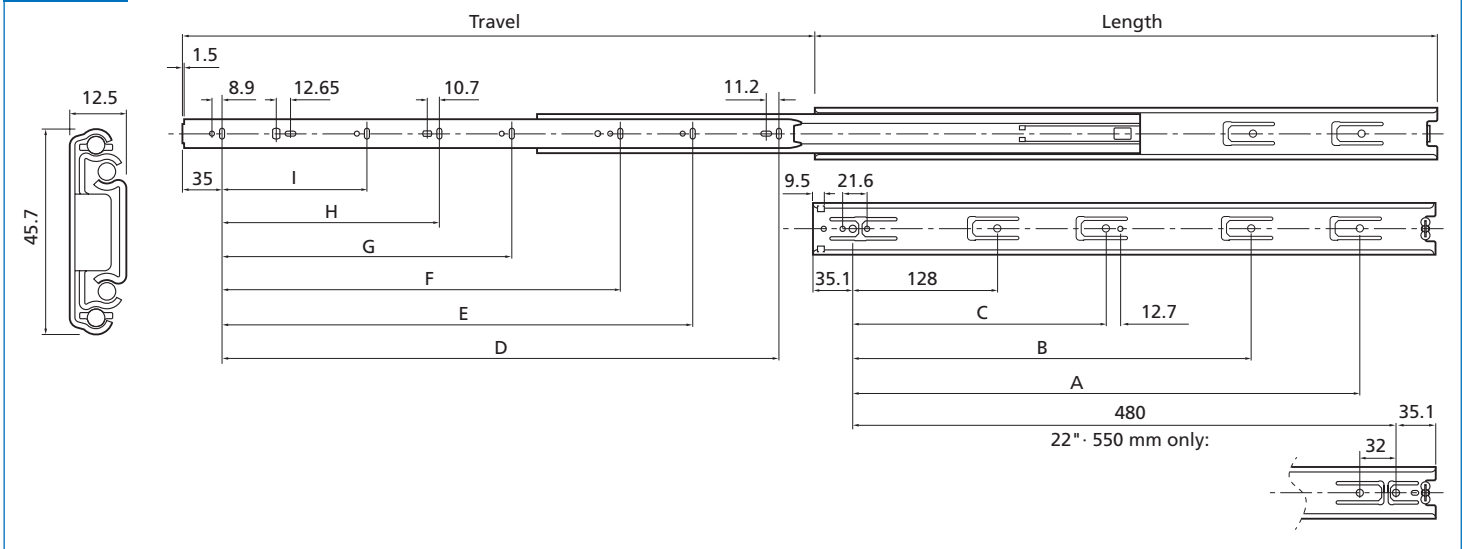

11416 04		Length		Travel		A		B		C		D		E		F		G		H		I		Load			
Item-No.	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	Inches	mm	lbs	kg	
11416 04 011	10	250	11	279								7-9/16	192												65	29	
11416 04 012	12	300	13	330						8-13/16	224	9-1/2	242								5	128			72	33	
11416 04 020	14	350	15	381						5	128	11-3/4	298												81	36	
11416 04 013	16	400	17	432				12-9/16	320	8-13/16	224	13-1/2	342								5	128			90	40	
11416 04 014	18	450	19	483				13-7/8	352	8-13/16	224	15-7/16	392			12-9/16	320				5	128			100	45	
11416 04 015	20	500	21	534				16-3/8	416	8-13/16	224	17-3/8	442			12-9/16	320				5	128			90	40	
11416 04 016	22	550	23	584				12-13/16	325	8-13/16	224	19-3/8	492	16-3/8	416						5	128			81	36	
11416 04 017	24	600	25	635	18-7/8	480	13-7/8	352	8-13/16	224	12-3/8	542			16-3/8	416				8-13/16	224	5	128			72	33
11416 04 018	26	650	27	686	21-7/16	544	13-7/8	352	8-13/16	224	23-5/16	592	21-3/8	544	16-3/8	416				8-13/16	224	5	128			65	29
11416 04 019	28	700	29	737	21-7/16	544	13-7/8	352	8-13/16	224	25-1/4	642	21-3/8	544	16-3/8	416	11-3/8	288	8-13/16	224	5	128			59	26	