



Battery-operated light

With motion sensor, rechargeable, 120 x 65 mm (4 3/4" x 2 9/16")

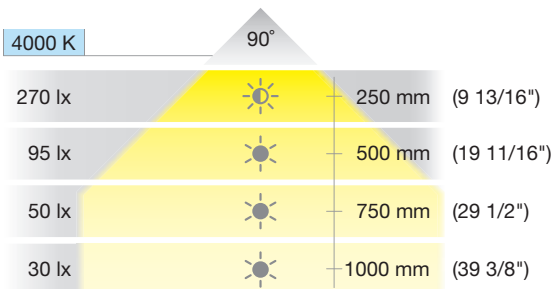

Häfele Loox LED 9004

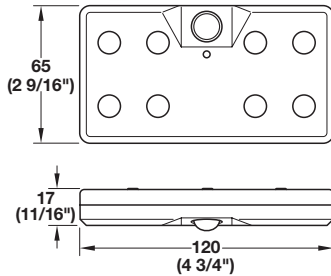

- > Version: With motion detector, twilight switch with built-in rechargeable lithium-ion battery
- > Material/Color: Plastic, silver colored
- > L x W: 120 x 65 mm (4 3/4" x 2 9/16")
- > Height: 17 mm (11/16")
- > Energy efficiency class: A++
- > Degree of protection: IP20
- > Number of LEDs: 8
- > Sensor range: 0–2000 mm (0–78 3/4")
- > Sensor angle: 120°
- > Delay time: 30 sec.
- > Operating time: 8 hrs.
- > Charging time: 3 hrs.
- > Two operating modes: Motion: permanently active motion detector
Auto: motion detector active with residual brightness of <5 lx
- > Mounting: Mounting plate for screw fixing; light for sliding on
- > Supplied with: 1 light with mounting plate for screw fixing and 0.8 m micro-USB cable



The light can be recharged using the supplied micro-USB cable

Color temperature	Wattage	Luminous flux	Luminous efficacy	Color rendering index CRI	Item No.
K	W	lm	lm/W	R _a	
4000	0.8	55	69	>90	833.87.021