 


Round LED panel light with interchangeable trim finishes



WET




COLOR TEMPERATURE SWITCH



MULTIPLE TRIM COLORS



If you are looking for a sleek, attractive LED option for your ceilings, then our color changing panel light with interchangeable trims is the perfect choice. With the flick of a switch, you have the ability to select one of three pre-set color temperatures - 3000, 4000 and 5000 K - convenience at your fingertips.

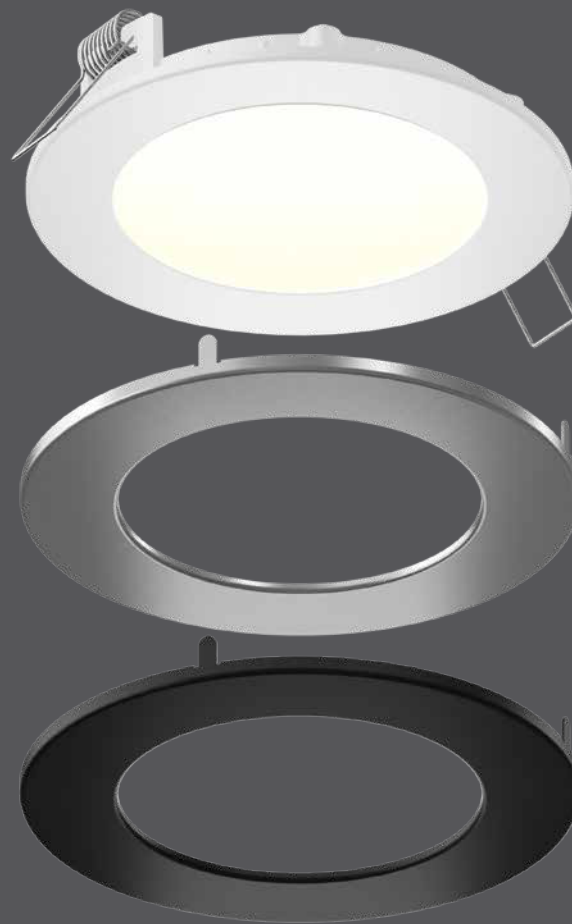

Model	Size	Watts	Delivered lumens	LED lumens	CRI	Color °T	Voltage
SPN4-CC-3T	4"	11 W	800 lm	850 lm	90	3000-4000-5000 K	120 V
SPN6-CC-3T	6"	14 W	1060 lm	1100 lm	90	3000-4000-5000 K	120 V

Specifications

Every fixture includes a junction box with integrated dimmable driver
 Can be daisy chained
 Minimal heat emission
 Aluminum construction
 IC certification (suitable for direct contact with insulation)
 Air-tight certified as per ASTM E283-04
 Over 50,000 hours of service life
 3 interchangeable trim colors
 Switch-selectable CCT: 3000 K/4000 K/5000 K
 110° beam angle
 Suitable for wet locations
 Refer to website for dimmer compatibility
 Ideal operating temperature: -20° to 40° C
 5-year warranty

Finish

- **BK** Black
- **SN** Satin Nickel
- **WH** White

Accessories

- REC-3CC-EXT108**
108" extension cable
- RFP-UNI**
Universal rough-in plate
- RFP-46**
Rough-in plate for 4" and 6" models

Order example



SPN4-CC-3T

Dimmable 4" recessed downlight, black/satin nickel/white finishes, with 3 switch-selectable CCT's: 3000 K, 4000 K, 5000 K




Note

Other Color °T and Finishes available, but may require MOQ's and longer lead times. Please contact your DALI representative for more information.

  SPN4-CC-3T



SPN6-CC-3T

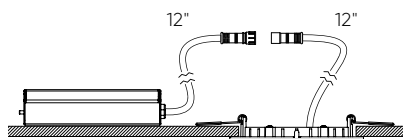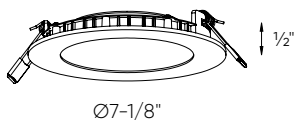 

5" x 3-1/2" x 1-1/4"

