



Xerox® Phaser® 3330 Printer and Xerox® WorkCentre® 3335/3345 Multifunction Printer

Powerful, Built-In Productivity and Ready-To-Go Reliability



High-performance environments need higher-functioning devices.

Introducing the Phaser® 3330 and WorkCentre® 3335/3345—designed to boost productivity with easy connectivity, day-in, day-out dependability and transformative features—ready to work.

Convenience and Connectivity

- **Wireless wonders.** Internal Wi-Fi connectivity comes standard for untethered mobility and the freedom to put your printer or multifunction device right where you need it. Our Wi-Fi installation wizard and Wi-Fi Print Setup (WPS) make getting connected secure and simple. And, with Wi-Fi Direct®, mobile devices can connect directly and securely.
- **Upwardly mobile.** With support for Apple® AirPrint™, Google Cloud Print™, Xerox® Print Service Plug in for Android™ and Mopria®, you can print emails, photos and important documents from a wide range of mobile devices, instantly, and without complicated setup.
- **Increase security and control.** With optional USB card readers, you can enhance your office security and control costs by integrating with many popular pull print and authentication solutions.
- **Ready to pair.** Now workers can easily print from Android-based mobile phone and tablets with Near Field Communication (NFC) tap-to-pair.

Performance and Productivity

- **Multifunction productivity.** The space-saving WorkCentre 3335/3345 Multifunction Printer (MFP) helps you conserve energy and reduce supplies costs by combining the functions of a copier, printer, color scanner and fax into one affordable device.
- **Outstanding performance.** With hefty processing power and standard memory, you'll see your first print faster and get print speeds up to 42 ppm.
- **Print more for longer.** An optional second paper tray lets you load an extra 550 sheets at one time for extended interruption-free printing.
- **See the difference.** Your documents will show exceptional sharpness with up to 1200 x 1200 dpi image quality.
- **Reliable endurance.** A monthly duty cycle up to 80,000 prints means it is capable of high-demand print environments*.
- **Economic efficiency.** Available high capacity print cartridges reduce your total cost of ownership and demand less frequent replacement.

* 50,000 prints for WorkCentre 3335

Easy and Able

- **Touch and go.** The WorkCentre 3335/3345 Multifunction Printer takes walkup simplicity to a new level, with a larger 4.3-inch color touchscreen interface.
- **Wherever, whenever and however.** Scan to email, or scan-to and print-from from a USB memory drive right at the device. You can even print directly from the cloud with a few simple steps.
- **Easy management.** With Xerox® CentreWare® Internet Services, remote device administration is handled with ease right from your computer's browser.
- **Stay secure.** Keep your sensitive documents away from unintended recipients with the latest security features, including IPsec, SNMPv3, IP Filtering and Secure Print.



Xerox® Phaser® 3330 Quick Facts


- Print up to 42 ppm Letter / 40 ppm A4
- Built-in Wi-Fi connectivity
- Standard 250-sheet paper capacity
- 50-sheet Bypass Tray
- Up to 1200 x 1200 dpi image quality

WxDxH:

14.4 x 14.4 x 11.4 in. /
366 x 366 x 289.6 mm

Weight:

23.37 lb / 10.6 kg

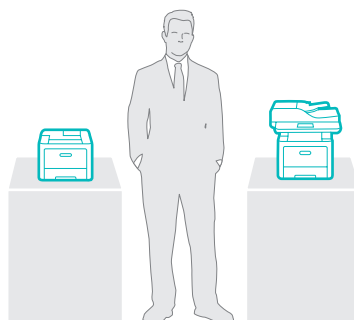

Xerox® WorkCentre® 3335/3345 Quick Facts

- Print up to 42 ppm Letter / 40 ppm A4 (WorkCentre 3345)
- 50-sheet Automatic Document Feeder (ADF) with WorkCentre 3335
- 50-sheet Reversing Automatic Document Feeder (RADF) with WorkCentre 3345
- Built-in Wi-Fi connectivity
- Standard 250-sheet paper capacity
- 50-sheet Bypass Tray
- Up to 1200 x 1200 dpi image quality

WxDxH:


WorkCentre 3335: 16.3 x 16.6 x 17.7 in. / 414.6 x 420.6 x 449 mm
WorkCentre 3345: 18.5 x 17.5 x 19 in. / 469 x 444.3 x 482.6 mm

Weight:

WorkCentre 3335: 34.19 lb / 15.51 kg
WorkCentre 3345: 38.07 lb / 17.27 kg

Reliable and full-featured game-changing value.

The Xerox® WorkCentre® 3335/3345 Multifunction Printer builds on the outstanding print performance of the Xerox® Phaser® 3330, delivering a solid lineup of powerful productivity tools designed to make your daily office tasks more efficient than ever.

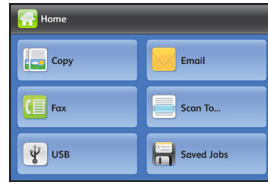

Phaser 3330



WorkCentre 3335



WorkCentre 3345

- 1 A 50-sheet Automatic Document Feeder (ADF) on the WorkCentre 3335 handles media sizes from 5.6 x 5.8 in. to 8.5 x 14 in. / 142 x 147 mm to 216 x 356 mm. Upgrade to the WorkCentre 3345 Multifunction Printer and get a 50-sheet Reversing Automatic Document Feeder (RADF) with the extra ability to scan, copy, fax and email two-sided originals.
- 2 A front-side USB port allows users to quickly print-from or scan-to any standard USB memory device.
- 3 Powerful color scanning capabilities include Scan to Email, Network Scanning, Scan to Folder and Scan to USB memory device.
- 4 Adjustable 50-sheet bypass tray accepts custom media sizes from 3 x 5 in. to 8.5 x 14 in. / 76 x 127 mm to 216 x 356 mm.
- 5 250-sheet input tray accepts custom media sizes from 3.9 x 5.8 in. to 8.5 x 14 in. / 99 x 147 mm to 216 x 356 mm.
- 6 Choose an additional 550-sheet paper tray and increase total capacity to 850 sheets.
- 7 150-sheet output tray.
- 8 The WorkCentre 3335/3345 includes an intuitive front panel for configuring device settings and programming jobs.
- 9 Easily install a USB card reader with the convenient Card Reader Bay.

Xerox® Phaser® 3330 Printer and Xerox® WorkCentre® 3335/3345 Multifunction Printer

	Phaser 3330	WorkCentre 3335	WorkCentre 3345
Speed	Up to 42 ppm Letter / 40 ppm A4	Up to 35 ppm Letter / 33 ppm A4	Up to 42 ppm Letter / 40 ppm A4
Duty Cycle	Up to 80,000 pages / month ¹	Up to 50,000 pages / month ¹	Up to 80,000 pages / month ¹
Paper Handling Paper Input	Standard	NA	Automatic Document Feeder (ADF): 50 sheets: Custom sizes: 5.6 x 5.8 in. to 8.5 x 14 in. / 142 x 147 mm to 216 x 356 mm
	Optional	Bypass Tray: 50 sheets; Custom sizes: 3 x 5 in. to 8.5 x 14 in. / 76 x 127 mm to 216 x 356 mm	Reversing Automatic Document Feeder (RADF): 50 sheets: Custom sizes: 5.6 x 5.8 in. to 8.5 x 14 in. / 142 x 147 mm to 216 x 356 mm
		Tray 1: 250 sheets; Custom sizes: 3.9 x 5.8 in. to 8.5 x 14 in. / 99 x 147 mm to 216 x 356 mm	
		Additional Tray: 550 sheets; Custom sizes: 3 x 5 in. to 8.5 x 14 in. / 76 x 127 mm to 216 x 356 mm	
Paper Output	150 sheets		
Automatic Two-sided Printing	Standard		
Print First-print-out Time	As fast as 6.5 seconds ²		
Print Resolution (max)	Up to 1200 x 1200 dpi image quality		
Processor	1 GHz		
Memory	512 MB	1.5 GB	
Connectivity	USB 2.0 (front and rear ports), 10/100/1000Base-T Ethernet, Wi-Fi		
Page Description Languages	Adobe® PostScript® 3™ compatible, PCL® 5e, 6, PDF Direct, TIFF, JPEG		
Print Features	Watermark, Collation, Auto 2-sided prints, N-up, Poster, Booklet print, Custom page size, Fit to page, Scaling, Draft mode, Earth Smart mode, Print from USB, Job scheduling, Print from local drive, Save, Save and Print		
Mobile Printing and Apps	Standard	Apple® AirPrint™, Google Cloud Print™ ³	
	Free Download	Xerox® Print Service Plug-in for Android™, Mopria®	
Copy First-copy-out Time		As fast as 13 seconds from the platen	
Copy Resolution (max)	NA	Up to 600 x 600 dpi	
Copy Features	NA	Automatic background suppression, Darkness control, ID Card Copy, Margin shift, N-up, Job build, Photo mode, Program Ahead, Booklet creation, Book copying with center erase, Job interrupt, Edge erase, Poster copying	
Fax ⁴ Fax Features	NA	33.6 Kbps with MH/MR/MMR/JBIG/JPEG compression, Address book (up to 200 speed dials, 209 group dials), Resolution up to 300 x 300 dpi, Auto redial, Auto reduction, Delayed Send, Fax Forward to Email/ Fax, Junk fax protection, Memory Receive, PC Fax (Windows® only), Secure Fax, Color Fax Send	
Scan Scan Destinations	NA	Scan to Network Computer (SMB/ FTP), Scan to Email (SMTP/POP3), WSD, Application (TWAIN Network), WIA (WSD Scan), Mac® 10.9 or later (Network/Mac ICA), USB	
	Scan Features	Up to 600 x 600 dpi (optical); Maximum 4800 x 4800 dpi (enhanced), 8-bit grayscale, PDF/JPEG/TIFF (single and multi-page)	
Security	802.1x, Secure Print, Secure HTTPS (SSL/TLS), Secure IPP, SSL, IP Filtering, IPv6, SNMP v3, IPsec, WEP (64-/128-bit), WPA2-PSK (AES) and WPA/WPA2-Personal and WPA/WPA2-Enterprise	802.1x, Secure Print, Secure HTTPS (SSL/TLS), Secure IPP, SSL, IP Filtering, IPv6, SNMP v3, WEP (64-/128-bit), WPA2-PSK (AES) and WPA/WPA2-Personal and WPA/WPA2-Enterprise, Network Address Book Authentication (LDAP, Windows Kerberos)	
Accounting	Xerox® Standard Accounting (Print)	Xerox® Standard Accounting (Copy, Print, Scan, Fax, Email)	

Device Management

Xerox® CentreWare® Internet Services, CentreWare Web, Email alerts, Apple® Bonjour®

Print Drivers

Microsoft® Windows Vista® and later, Mac OS® 10.8 and later, various Linux® and Unix® distributions, Xerox® Global Print Driver®, Xerox® Mobile Express Driver®

Media Handling

Automatic Document Feeder (3335): 16 lb – 28 lb Bond / 60 – 105 gsm; Reversing Automatic Document Feeder (3345): 12.5 lb – 28 lb Bond / 50 – 105 gsm; Bypass Tray: 16 lb Bond – 58 lb Cover / 60 – 220 gsm; Tray 1: 16 lb – 43 lb Bond / 60 – 163 gsm

Media Types

Archive, Bond, Cardstock, Custom, Envelopes, Heavyweight, Labels, Lightweight, Plain paper, Pre-printed, Recycled, Transparencies

Certifications

To view the latest list of certifications, go to www.xerox.com/OfficeCertifications.

Electrical

Power: 110 – 127 VAC, 50/60 Hz, 7A or 220 – 240 VAC, 50/60 Hz, 5A; Power Consumption: Operation: max 700 W; Standby: max 50 W; Sleep: max 3.5 W; Power off: max 0.1 W

Operating Environment

Temperature: Storage: 32° to 104° F / 0° to 40° C; Operating: 50° to 90° F / 10° to 32° C; Humidity: Operating: 20% to 80%; Sound power and pressure levels: 3330: Printing: 54 dB(A), Standby: 26 dB(A); 3335: Printing/copying: 55 dB(A), Standby: 26 dB(A); 3345: Printing/copying: 57 dB(A), Standby: 26 dB(A); Warm-up time (from sleep mode): as fast as 35 seconds

What Comes in the Box

- Phaser 3330, WorkCentre 3335 or WorkCentre 3345
- Standard Toner Cartridge (2,600 pages⁵)
- Drum Cartridge (30,000 pages⁵)
- Software and Documentation CD (with Safety, Regulatory, Recycling and Disposal Guides), Print Drivers and Warranty Statement
- Installation Guide
- Quick Use Guides
- Power Cable
- Fax Cord (WorkCentre 3335 and WorkCentre 3345 only)

Supplies

Extra-high Capacity Print Cartridge: 15,000 std. pages⁵ 106R03624
High Capacity Print Cartridge: 8,500 std. pages⁵ 106R03622
Standard Capacity Print Cartridge: 2,600 std. pages⁵ 106R03620
Drum Cartridge: 30,000 pages⁶ 101R00555

Options

550-sheet Paper Tray 097N02254
NFC Enablement Kit 097N02255
Phaser 3330 Card Reader Enablement Kit (with card reader) 497K18000
Phaser 3330 Card Reader Enablement Kit (without card reader) 497K18010
WorkCentre 3335/3345 Card Reader Enablement Kit (with card reader) 497K17980
WorkCentre 3335/3345 Card Reader Enablement Kit (without card reader) 497K17990

¹ Maximum volume capacity expected in any one month.

Not expected to be sustained on a regular basis.

² Printing from USB.

³ Depending on specific mobile device versions or vendor, the mobile device may require a free download of the app from the appropriate store.

⁴ Requires analog phone line.

⁵ Average standard pages. Declared Yield in accordance with ISO/IEC 19752.

Yield will vary based on image, area coverage and print mode.

⁶ Approximate pages. Declared Yield based on letter-/A4-size 20 lb (75 gsm) pages.

Yield will vary based on media type, size, weight, orientation and usage patterns.

For more information, visit us at www.xerox.com/office.

