

DORCY®

ULTRA HD 2000L RECHARGEABLE FLASHLIGHT

Flashlight Parts

Military Grade Aluminum

Micro USB Port (input)

Twist open/close port cover

GREEN/RED LED Indicator Lights
(Can be seen through the input/output ports while charging)

USB Port (output)

Rechargeable:

- A) Equipped with a micro USB cable for quick and convenient charging (Included)
- B) Red Solid : Flashlight is charging
- C) Green Solid: Flashlight is fully charged
- D) Charging time: 5-6 hours

4 Mode Power Switch:

- SPOT + COB
- SPOT HIGH
- SPOT LOW
- COB FLOOD

LITHIUM-ION

Includes:
4000mAh 18650 Lithium-ion rechargeable battery

Power bank function:

- A) Designed to serve as a power bank for smart phones and other devices in an emergency (cords to specific devices not included)
- B) Red Flash: Charging device
- C) Green Solid : Device is fully charged

Beam Operation

COB Flood Beam

Spot Beam

Note: If flashlight is in any mode for more than 5 seconds the flashlight will reset to SPOT + COB mode once flashlight is turned off, then on again.

BATTERY CARE: Your product is powered by a rechargeable battery. Do not leave fully charged battery connected to charger, since this will reduce its lifetime. Leaving product in extreme cold or heat will reduce battery life. For optimal performance store product at temperatures between 59°F to 77°F. Battery performance may be reduced in temperatures well below freezing. Fully charged batteries will lose charge over time, if left unused.

BATTERY WARNING: Rechargeable battery is built-in. Do not attempt to remove or replace battery. The battery in this product is at risk of fire, explosion, or may cause chemical burns if mistreated.

Performance Index

FL1 STANDARD	FLOOD+SPOT	SPOT HIGH	SPOT LOW	FLOOD
	2000 LUMENS	1000 LUMENS	300 LUMENS	1500 LUMENS
	3h 30min	5h 30min	17h 30min	4h
	195m			

Battery Charge Options

Only use one port (input/output) at a time when charging

USB Port (PC or Laptop)

USB Wall Adapter

Auto USB Charger


DORCY®

LAMPE DE POCHE RECHARGEABLE ULTRA HD 2000L

Pièces de lampe de poche



Fonctionnement du faisceau

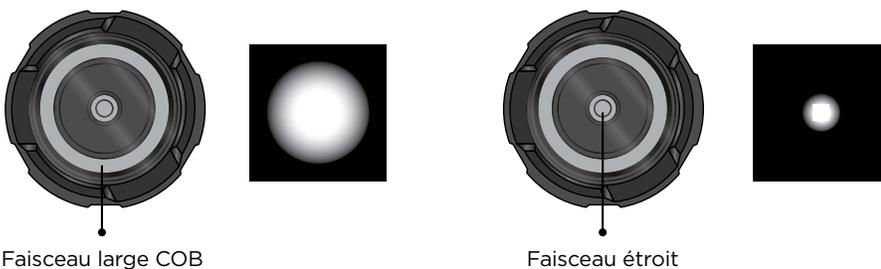

Remarque : Si la lampe de poche est dans n'importe quel mode pendant plus de 5 secondes, la lampe de poche se réinitialisera en mode SPOT + COB une fois la lampe de poche éteinte, puis rallumée.

ENTRETIEN DE LA BATTERIE : Votre produit est alimenté par une batterie rechargeable. Ne laissez pas la batterie complètement chargée connectée au chargeur, car cela réduirait sa durée de vie. Laissez le produit dans un froid ou une chaleur extrême réduira la durée de vie de la batterie. Pour des performances optimales, stockez le produit à des températures comprises entre 59 °F et 77 °F. Les performances de la batterie peuvent être réduites à des températures bien inférieures au point de congélation. Les batteries complètement chargées perdront leur charge au fil du temps si elles ne sont pas utilisées.

AVERTISSEMENT DE LA BATTERIE: La batterie rechargeable est intégrée. N'essayez pas de retirer ou de remplacer la batterie. La batterie de ce produit présente un risque d'incendie, d'explosion ou peut provoquer des brûlures chimiques en cas de mauvais traitement.

Index des performances

FL1 STANDARD	FLOOD+SPOT	SPOT HIGH	SPOT LOW	FLOOD
	2000 LUMENS	1000 LUMENS	300 LUMENS	1500 LUMENS
	3h 30min	5h 30min	17h 30min	4h
	195m			
	1m			

Options de chargement de la batterie

