

Construction Reamers

HIGH SPEED STEEL
Fractional / Black Oxide


PACKAGING:
All sizes are individually packaged.

4290 Construction Reamers



SPIRAL FLUTE / HEX NUT / CAR LENGTH

Construction or Car Reamers are especially adapted for heavy duty reaming as encountered in the fabrication of structural steel assemblies. They are tapered at the point to facilitate entering of holes which are out of alignment. Available in Spiral Flute and High Spiral Flute designs with 3-Flat Straight Shanks, or with Hex Nut Shanks.

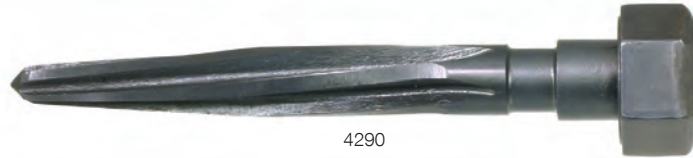

4290

Size	Hex Dia.	Flute Length	Overall Length	4290 EDP No.
1/2"	1-1/16"	4"	5-1/2"	429A132
9/16"	1-1/16"	4"	5-7/8"	429A136
5/8"	1-1/16"	4-1/2"	6"	429A140
11/16"	1-1/16"	4-1/2"	6-3/8"	429A144
3/4"	1-1/4"	5"	7"	429A148
13/16"	1-1/4"	5"	7"	429A152
7/8"	1-7/16"	5"	7"	429A156
15/16"	1-7/16"	5"	7"	429A160
1"	1-7/16"	5"	7"	429A164

Size	Hex Dia.	Flute Length	Overall Length	4290 EDP No.
1-1/16"	1-5/8"	5"	7"	429A204
1-1/8"	1-5/8"	5"	5"	429A208
1-3/16"	1-13/16"	5"	7"	429A212
1-1/4"	1-13/16"	5"	7"	429A216
1-5/16"	2"	5"	7-7/8"	429A220
1-3/8"	2"	5"	7-7/8"	429A224
1-7/16"	2"	5"	7-7/8"	429A228
1-1/2"	2"	5"	7-7/8"	429A232
1-9/16"	2"	5"	7-7/8"	429A236

4290E Construction Reamers

SPIRAL FLUTE / HEX NUT / CAR LENGTH

Construction or Car Reamers are especially adapted for heavy duty reaming as encountered in the fabrication of structural steel assemblies. They are tapered at the point to facilitate entering of holes which are out of alignment. Available in Spiral Flute and High Spiral Flute designs with 3-Flat Straight Shanks, or with Hex Nut Shanks.



4290E

Size	Hex Dia.	Flute Length	Overall Length	4290E EDP No.
11/16"	1-1/16"	4-1/2"	5-7/8"	429E144
13/16"	1-1/4"	5"	6-3/8"	429E152
15/16"	1-7/16"	5"	6-3/8"	429E160
1-1/16"	1-5/8"	5"	6-7/8"	429E204