



SIDETRAK SOLO PRO FREESTANDING MONITORS

START GUIDE



240.580.8725 | customerservice@sidetrak.com

WELCOME



Congratulations on your purchase! We are confident that you will be satisfied with your new portable monitor. Our mission is to bring joy to people at work by offering the portability of a laptop with the productivity of working on two screens.

The benefits of a second screen will make your worklife easier!

WELCOME TO A MORE PRODUCTIVE YOU!

CONTENTS




- 1-2 Product Interface
- 3 What's In the Box
- 4 Operating Instructions
- 5 Frequently Asked Questions
- 6-7 Technical Specifications
- 8 Contact Us

PRODUCT INTERFACE



SideTrak Solo Pro Portable Monitor

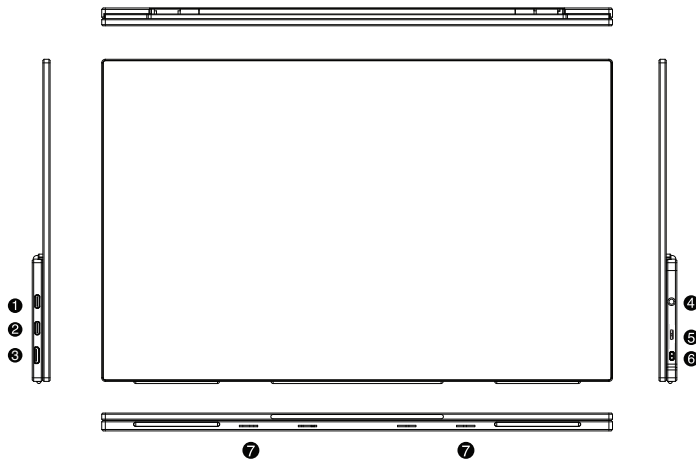


1 2		Type-C USB Input	USB-C type power and graphics connector
3		Mini HDMI Input	HDMI type power connector
4		Headphones Input	External audio connector, headset
5		Wheel / Menu	Adjust menu, control brightness, control volume
6		On/ Off Button	Power on and off / Return button for menu
7		Speakers	Audio output

PRODUCT INTERFACE



SideTrak Solo Touchscreen Pro Portable Monitor

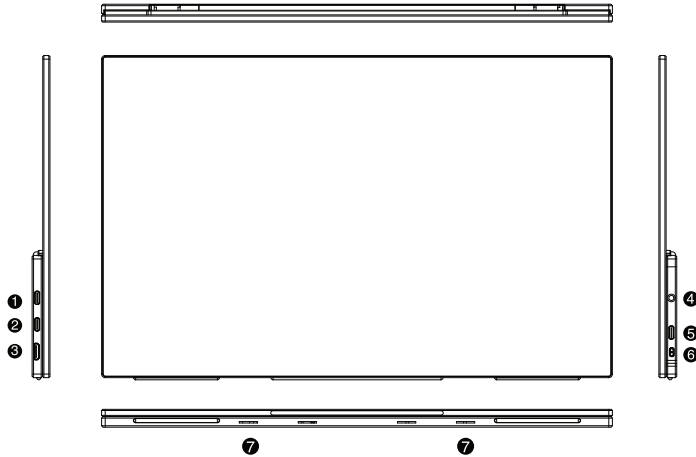


1 2		Type-C USB Input	USB-C type power and graphics connector
3		Mini HDMI Input	HDMI type power connector
4		Headphones Input	External audio connector, headset
5		Type-C USB Input	USB-C type power and graphics connector
6		On/ Off Button	Power on and off / Menu
7		Speakers	Audio output

WHAT'S IN THE BOX



Monitor Screen

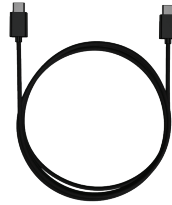

USB-C Cable



USB-A to USB-C
Cable



Mini HDMI
Cable



USB-C to USB-A
Female Cable
(only for touchscreen monitor)

OPERATING INSTRUCTIONS



1. Plug In

If your laptop has a USB-C port, connect one end of the USB-C to USB-C cable to the laptop and the other end to the monitor. Some laptops may not provide enough power to the monitor. If the monitor won't turn on, connect the USB-A to USB-C cable along with the mini HDMI cable.

If your laptop does not have a USB-C port, connect one end of the USB-A to USB-C cable to the laptop and the other end to the monitor. Then also connect the mini HDMI cable.

Monitor must be plugged in to power on.

2. Turn On

Press and hold the On/Off button for 3 seconds to power on your monitor.

3. Adjust Stand

Pull the stand out and adjust to your viewing preference.

4. Adjust Settings

On the non-touch screen monitor, push the wheel/menu button to bring up the menu. Move the wheel/menu button up or down to scroll and push wheel/menu button to select. Short press the on/off button to return.

On the touch screen monitor, short press the on/off button to bring up the menu. Make selections by touching the screen.

- To prevent any damage to the monitor, please turn off and unplug the monitor when left unattended for long periods of time.

FAQ



Q: My monitor won't power on

A: If you are not using a USB-C to USB-C cord, make sure your monitor is connected to your laptop with both the HDMI cord and the USB-A to USB-C. Then, press and hold the on/off button to power up the monitor.

Q: Why do I have to plug in two cords if I don't have a USB-C port on my laptop?

A: The USB-C to USB-C cord is strong enough to communicate power and graphics through one cord. If you can't use the USB-C to USB-C cord you will have to use the HDMI to HDMI cord along with the USB-A to USB-C cord so that it can communicate power through one cord and graphics on the other.

Q: How do I adjust brightness?

A: If you have the non-touch screen, push the wheel/menu button to bring up the menu, then move the wheel/menu button up and down to get to the brightness setting. Push the wheel/menu button to select the brightness setting. Then, move the wheel/menu button up or down to adjust brightness to your preference.

Q: The touch feature will not work while connected with an HDMI cable

A: If you are using the HDMI cable, you also need to use the USB-C cable in order for the touch function to work. Touchscreen capabilities do not work with mobile phones and might not work on some MacBooks.

TECHNICAL SPECIFICATIONS

SideTrak Solo Pro Portable Monitor

Size	15.8 inch	
Model Name	STFRHD16BL	
Panel	BOE/AUO/INL	
LED Panel	Display size	15.8" LED-Backlight
	Brightness (Typical)	300cd/m2
	NTSC	45%
	Contrast (Typical)	800:1 (Typical)
	Active Area (mm)	344. 16X193. 59mm
	Pixel Pitch (mm)	1.7(H) X 1.7(V)
	Resolution (H x V)	1920 x 1080
	Aspect Ratio	16:9
	Response Time (Typical)	8ms
	View Angles LR, UD(CR>10)	H 170°/ V 170°
	Panel Surface	Anti-glare
	Display Colors	16.7 M
PC Input Range	Vertical Freq.	50 to 60Hz
	Max. display frequency	1920 x 1080 / 60Hz
Interface	Input 1	TYPE-C x 2 (USB-C)
	Input 2	Mini HDMI x 1

Output Terminal	Earphone	3.5mm Earphone x 1
	Speaker (Typical)	1W*2
Power	Consumption (Typical)	8W
	PD POWER	DC: 5V-3A/9V-3A/20V-2A
	Power Mode Light	Power on: RED (LED)
Physical	Dimensions (W*D*H)	9 x 14 x 0.37 in
	Net Weight	1.22 lb
	Gross Weight	3.93 lb
	Tilt	90°~ 45°, 0°
Controls	Front Control	Standard
	On Screen Display	Standard OSD format
	Color	9300,6500, User Mode
	Preset Mode	Standard, TXT, Movie, Game FPS, RTS

TECHNICAL SPECIFICATIONS

SideTrak Solo Touchscreen Pro Portable Monitor

Size	15.8 inch	
Model Name	STFRHDTC15BL	
Panel	BOE/AUO/INL	
LED Panel	Display size	15.8" LED-Backlight
	Brightness (Typical)	250cd/m2 (Typical)
	NTSC	72%
	Contrast (Typical)	800:1 (Typical)
	Active Area (mm)	344. 16X193. 59mm
	Pixel Pitch (mm)	0.17925(H)X0.17925(V)
	Resolution (H x V)	1920 x 1080
	Aspect Ratio	16:9
	Response Time (Typical)	8ms
	View Angles LR, UD(CR>10)	85/85/85/85
	Panel Surface	glare (AF)
	Display Colors	16.7M
PC Input Range	Vertical Freq.	50 to 60Hz
	Max. display frequency	1920 x 1080 / 60Hz
Interface	Input 1	TYPE-C x 2 (USB-C)
	Input 2	Mini HDMI x 1
	Input 3	Micro USB

Output Terminal	Earphone	3.5mm Earphone x 1
	Speaker (Typical)	1W*2
Power	Consumption (Typical)	8W
	PD POWER	DC: 5V-3A/9V-3A/20V-2A
	Power Mode Light	Power on: RED (LED)
Physical	Dimensions (W*D*H)	9 x 14 x 0.37 in
	Net Weight	1.9 lb
	Gross Weight	4.17 lb
	Tilt	90°~ 45°, 0°
Controls	Front Control	Touch on screen
	On Screen Display	Standard OSD format
	Color	9300,6500, User Mode
	Preset Mode	Standard, TXT, Movie, Game FPS, RTS

CONTACT US



If you have any questions, we are here to help!

240.580.8725

customerservice@sidetrak.com

<https://sidetrak.com>

Follow us!

Stay updated on product launches, news, and tips.



@sidetrak.monitor



@sidetrakmonitor



facebook.com/sidetrakmonitor



SIDETRAK