




PRODUCT DESCRIPTION

Bejeweled in thousands of crystals over gleaming K9 chrome, the Bijou Collection sparkles with the unmistakable radiance of rare diamonds. Encasing a warm, soft glow within, the smooth orbs of chrome come to life as light shimmers and dances off the crystal-encrusted surface. Whether as a pendant, sconce, or flush mount, Bijou adorns the room in beauty and richness.

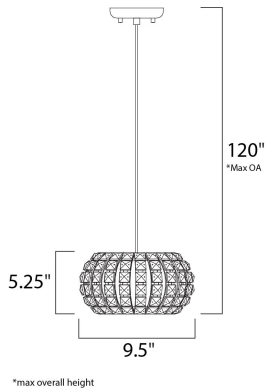

MEASUREMENTS

DIMENSION : 9.5" W x 5.25" H
 MAX OAH : 120" OAH
 HANGING WEIGHT : 4.85 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 1,500 Rated
 BULB : 3 x 40W Xenon G9 , 120W Total
 BULB INCLUDED : (Included)
 DIMMABLE : Yes
 COLOR_TEMP : 2900K

FINISHES OPTION



GLASS

Crystal 20

MATERIAL

Crystal, Acrylic, Steel

RATINGS

cETLus
 Dry Location



ADDITIONAL

SLOPE: 120
 RATED LIFE 2000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336
 P. 626.956.4200 | F. 626.956.4225 | et2online.com