


PRODUCT DESCRIPTION

Rectangular Beveled Crystals are banded together to form soft square cylinders which are illuminated by LED that creates a brilliant lighting effect. Some items include metal chassis of Black which frame the crystal for a beautiful silhouette.

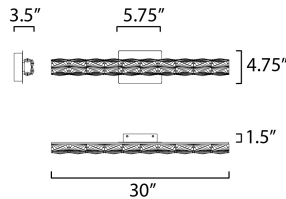

MEASUREMENTS

DIMENSION : 30" L 5.5" H x 3.25" Ext
 BACK PLATE : 4.75" W x 1.5" H x 15" HCO
 HANGING WEIGHT : 5.98 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 2,420 Rated (1,532 Del.)
 BULB : 1 x 23W LED PCB Integrated , 23W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Triac CL or ELV
 CRI : 90+ CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Omni

FINISHES OPTION

 Polished Chrome

GLASS

Crystal 20

MATERIAL

Steel, Crystal, Stainless Steel

RATINGS

cETLus
 Damp Location
 ADA



ADDITIONAL

INSTALL UP/DOWN: All
 RATED LIFE 25000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336
 P. 626.956.4200 | F. 626.956.4225 | et2online.com