

# I.147 | Tapered handles

Duroplast

METRIC

RoHS

PF

+230 °F  
-4 °F

## MATERIAL


Phenolic based (PF) Duroplast, black colour, glossy finish.

## STANDARD EXECUTION

Threaded blind hole.



Conversion Table	
1 mm = 0.039 inch	
L	
mm	inch
40	1.57
47	1.85
60	2.36
67	2.64
77	3.03
86	3.39

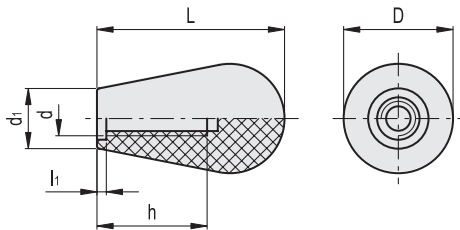

METRIC

Code	Description	D	L	d	d1	h	h1	⚖️
19801	I.147/40-M6	24	40	M6	14	25	3	16
19802	I.147/40-M8	24	40	M8	14	28	3.5	14
19901	I.147/50-M8	29	47	M8	16	28	3.5	25
19902	I.147/50-M10	29	47	M10	16	28	3.5	24
20001	I.147/60-M10	35	60	M10	19	35	8	46
20002	I.147/60-M12	35	60	M12	19	35	8	44
20101	I.147/75-M14	39	77	M14	22	45	6	72



Fixed & revolving handles