

I.281+x Revolving handles

Duroplast

INCH



PF




- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15

MATERIAL

Phenolic based (PF) Duroplast, black colour, glossy finish.

STANDARD EXECUTION

- Matte chrome-plated steel shank, cylindrical-head with hexagon socket and threaded end.
- Black oxide steel shank with plain end for push-fit fixation.

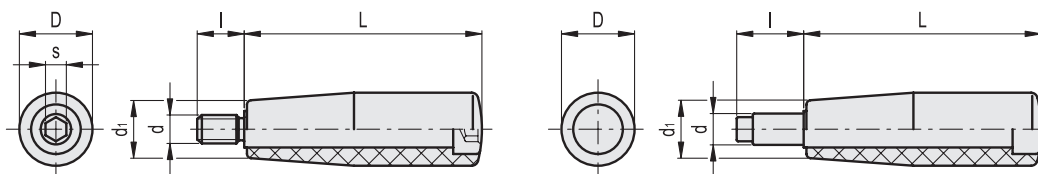

INCH

Code	Description	D	L	d2A	d+001	d1	l	s	
922311	I.281/40+x-1/4-20	0.71	1.57	1/4-20	-	0.59	0.51	5/32	0.07
922321	I.281/40+x-1/4	0.71	1.57	-	0.250	0.59	0.51	-	0.07
922411	I.281/50+x-5/16-18	0.83	1.97	5/16-18	-	0.67	0.59	3/16	0.13
922421	I.281/50+x-1/4	0.83	1.97	-	0.250	0.67	0.47	-	0.15
922511	I.281/65+x-5/16-18	0.91	2.56	5/16-18	-	0.75	0.67	1/4	0.21
922521	I.281/65+x-5/16	0.91	2.56	-	0.312	0.75	0.71	-	0.22
922611	I.281/80+x-3/8-16	1.02	3.15	3/8-16	-	0.83	0.71	1/4	0.32
922621	I.281/80+x-3/8	1.02	3.15	-	0.375	0.83	0.87	-	0.33
922711	I.281/90+x-3/8-16	1.1	3.54	3/8-16	-	0.87	0.71	5/16	0.41
922721	I.281/90+x-1/2	1.1	3.54	-	0.500	0.87	0.79	-	0.45

Fixed & Revolving handles

494

