

# I.601+x | Revolving handles

Technopolymer




## MATERIAL

High-resilience polypropylene based (PP) technopolymer, black colour, matte finish.

## STANDARD EXECUTIONS

- **I.601+x**: zinc-plated steel shank, hexagon socket at threaded end.
- **I.601+x-SST**: AISI 303 stainless steel shank, hexagonal socket at threaded end.

Conversion Table			
1 mm = 0.039 inch			
L			
mm	inch	mm	inch
28	1.10	80	3.15
40	1.57	90	3.54
50	1.97	102	4.02
56	2.20	116	4.57
65	2.56		

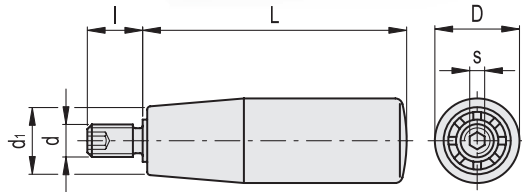

## I.601+x

METRIC

Code	Description	D	L	d6g	d1	l	s	⚖
24921	I.601/40+x-M6	18	40	M6	15	13	3	25
24931	I.601/50+x-M6	21	50	M6	17	13	3	35
24941	I.601/56+x-M6	22	56	M6	18	13	3	40
24951	I.601/65+x-M8	23	65	M8	19	15	4	68
24952	I.601/65+x-M10	23	65	M10	19	17	5	70
24961	I.601/80+x-M8	26	80	M8	21	15	4	75
24962	I.601/80+x-M10	26	80	M10	21	17	5	78
24971	I.601/90+x-M10	28	90	M10	22	17	5	85
24972	I.601/90+x-M12	28	90	M12	22	20	5	100

## I.601+x-SST

INOX STAINLESS STEEL

METRIC

Code	Description	D	L	d6g	d1	l	s	⚖
24925	I.601/40+x-M6-SST	18	40	M6	15	13	3	25
24935	I.601/50+x-M6-SST	21	50	M6	17	13	3	35
24955	I.601/65+x-M8-SST	23	65	M8	19	15	4	68
24965	I.601/80+x-M10-SST	26	80	M10	21	17	5	78
24975	I.601/90+x-M10-SST	28	90	M10	22	17	5	85



Fixed & revolving handles