

TLG. | Hook clamps

Steel or stainless steel





STANDARD EXECUTIONS

- **TLG.Z**: zinc-plated steel.
- **TLG.SST**: AISI 304 stainless steel.

SPECIAL EXECUTIONS ON REQUEST

- Hook clamps in unplated steel or nickel-plated steel.
- Catch brackets in different shapes and finishes.

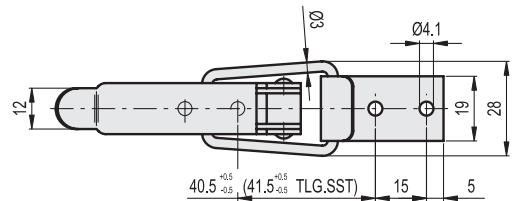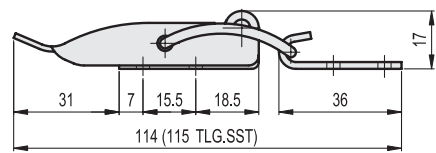

TLG.Z

METRIC

Code	Description	Max. working load [N]	Load at breakage [N]	
420111	TLG.Z-12/114+R	1000	2500	59

TLG.SST

INOX STAINLESS STEEL METRIC

420112	TLG.SST-12/114+R	1000	2500	59
--------	------------------	------	------	----

