

Sar  
COR



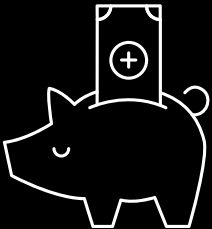
 

# TRADITION™ UPRIGHT

MENU

SC886E



TRADITION™ upright designed with a chrome hood for added durability in the toughest environments. Lowers cost of ownership with a 2,000 hour motor, shake out bag and chrome brushroll with replaceable bristle strips. Quick Kleen™ fan chamber helps diagnose and clear clogs for easy maintenance. Increase productivity with less downtime with a large-capacity, 18-qt. shake out bag and 50-foot cord.

 <b>BUILT TO LAST</b>	 <b>&gt;2,000 HOURS MOTOR LIFE</b>	 <b>COST OF OWNERSHIP</b>
 <b>HANDY FEATURES</b>	 <b>LOW MAINTENANCE COSTS</b>	

SPECIFICATIONS			
MFG#	SC886E	CLEANING WIDTH	12"
MOTOR	7 amp	CORD LENGTH	50'
CFM	145	SOUND	79 dBA
FILTRATION	n/a	BRUSH ROLL	53270
DUST CONTAINMENT	Shake Out Bag	BELT	52100C-12
DUST CAPACITY	18 qt.	CLEANING TOOLS	n/a
PACKAGING			
UPC	0 23169 10081 7	PACKAGE WEIGHT	19 lbs.
PRODUCT WEIGHT	15.8 lbs.	PACKAGE DIMENSIONS	20.5" x 15" x 8.5"
WARRANTY	2 Years - Parts & Labor		