

1. Product and Company Identification

Product identifier	Salt
Other means of identification	Sodium Chloride Sifto Safe Step Standard Salt Sifto Ice Salt Sifto Sodium Chloride Sifto Safe Step EnviroGuard QwikSalt Ice-A-Way IceAway Turbo IceAway Turbo Blue Safe Step 3300 Aspen Aspen Blue Safe Step 4300 Dual Blend Safe Step 4300 Dual Blend Blue EconoBlend 370 Winter Storm Winter Storm Blue Safe Step Pro Series 550 Safe Step Pro Series 570 Safe Step 6300 Enviro Blend Safe Step Pro Series 960 Choice Formula Safe Step Sure Paws Sifto Safe Step Sure Paws American Stockman Animal Nutrition Products Nature's Own water care products Sure Soft water care products Natural Salt water care Pro Soft water care products
Recommended use	De-icer. General industrial and water softening/conditioning purposes. Animal Nutrition.
Recommended restrictions	None known.
Manufacturer	Compass Minerals International 9900 West 109th Street, Suite 100 Overland Park, KS 66210 US Phone 913-344-9200 Emergency US CHEMTREC 1-800-424-9300 Emergency Canada CANUTEC 1-800-996-6666
CHEMTREC	1-800-424-9300
CANUTEC	1-800-996-6666

2. Hazards Identification

Physical hazards	Not classified.
Health hazards	Not classified.
Environmental hazards	Not classified.
OSHA defined hazards	Not classified.
Label elements	
Hazard symbol	None.
Signal word	None.
Hazard statement	The product and/or mixture does not meet the criteria for classification.
Precautionary statement	
Prevention	Observe good industrial hygiene practices.
Response	Wash hands after handling.
Storage	Store away from incompatible materials, i.e, strong oxidizing agents (see Section 10)
Disposal	Dispose of waste and residues in accordance with local authority requirements.
Hazard(s) not otherwise classified (HNOC)	None known.
Supplemental information	Not applicable.

3. Composition/Information on Ingredients

Salt and/or Salt Mixtures

Composition comments The criteria for listing components in this section are: Carcinogens, Respiratory Sensitizers, Mutagens, Teratogens and Reproductive toxins are listed when present at 0.1% or greater; components which are otherwise hazardous according to WHMIS/OSHA are listed when present at 1.0% or greater. Non hazardous components are not listed. The products pertaining to this SDS have various proportions of components which do not meet the listing criteria.

4. First Aid Measures

Inhalation Avoid breathing dust. If breathing is difficult, remove to fresh air and keep at rest in a position comfortable for breathing. Call a physician if symptoms develop or persist.

Skin contact Rinse skin with water/shower. Get medical attention if irritation develops and persists.

Eye contact Rinse with water. Get medical attention if irritation develops and persists.

Ingestion Rinse mouth. If ingestion of a large amount does occur, seek medical attention.

Most important symptoms/effects, acute and delayed Direct contact with eyes may cause temporary irritation.

Indication of immediate medical attention and special treatment needed Treat symptomatically.

5. Fire Fighting Measures

Suitable extinguishing media Salt and salt mixtures are non-combustible.

Unsuitable extinguishing media Not applicable.

Specific hazards arising from the chemical During fire, gases hazardous to health may be formed.

Special protective equipment and precautions for firefighters Use appropriate firefighting PPE as a general precaution.

Fire-fighting equipment/instructions Salt is not combustible and is thus not the material of concern for firefighting equipment or methods.

Specific methods In the event of a fire, equipment and methods that are consistent with the combusting material should be utilized.

General fire hazards No unusual fire or explosion hazards noted.

Hazardous combustion products Chlorine. Hydrogen chloride. Oxides of sodium.

Explosion data

Sensitivity to mechanical impact Not available.

Sensitivity to static discharge Not available.

6. Accidental Release Measures

Personal precautions, protective equipment and emergency procedures Restrict area to facilitate clean up.

Methods and materials for containment and cleaning up Stop the flow of material, if this is without risk. Prevent direct entry into waterways and sewers. Following product recovery, flush area with water if necessary. For waste disposal, see section 13 of the SDS.

Environmental precautions Avoid direct release into waterways and sewers.

7. Handling and Storage

Precautions for safe handling Use care in handling/storage. Avoid breathing dust.

Conditions for safe storage, including any incompatibilities Store in original tightly closed container. Store away from incompatible materials, i.e, strong oxidizing agents (see Section 10)

8. Exposure Controls/Personal Protection

Occupational exposure limits No exposure limits noted for ingredient(s).

Biological limit values No biological exposure limits noted for the ingredient(s).

Appropriate engineering controls

TWA PEL: No specific limits have been established for sodium chloride (a soluble substance). As a guideline, OSHA (United States) has established the following limits which are generally recognized for inert or nuisance dust. Particulates Not Otherwise Regulated (PNOR): 5mg/cu.m. Respirable Dust 8-Hour TWA PEL, 15mg/cu.m. Total Dust 8-Hour TWA PEL.

TWA TLV: No specific limits have been established for sodium chloride (a soluble substance). As a guideline, ACGIH (United States) has established the following limits which are generally recognized for inert or nuisance dust. Particulates (insolubles) Not Otherwise Classified (PNOC): 10mg/cu.m. Inhalable Particulate 8-Hours TWA TLV, 3mg/cu.m. Respirable Particulate TWA TLV.

Use process enclosures, local exhaust ventilation, or other engineering controls to control airborne levels below recommended exposure limits.

Individual protection measures, such as personal protective equipment

Eye/face protection	Safety glasses if eye contact is possible.
Skin protection	
Hand protection	If there is constant skin contact, rubber gloves are recommended.
Other	Wear suitable protective clothing.
Respiratory protection	No personal respiratory protective equipment normally required.
Thermal hazards	Not applicable.

General hygiene considerations

Always observe good personal hygiene measures, such as washing after handling the material and before eating, drinking, and/or smoking. Routinely wash work clothing and protective equipment.

9. Physical and Chemical Properties

Appearance	Crystalline.
Physical state	Solid.
Form	Solid.
Color	Varies
Odor	Odorless
Odor threshold	Not applicable
pH	6 - 8 (Neutral)
Melting point/freezing point	Not applicable
Initial boiling point and boiling range	Not applicable
Pour point	Not applicable
Specific gravity	Not applicable
Partition coefficient (n-octanol/water)	Not applicable
Flash point	Not applicable
Evaporation rate	Not applicable
Flammability (solid, gas)	Not applicable.
Upper/lower flammability or explosive limits	
Flammability limit - lower (%)	Not applicable
Flammability limit - upper (%)	Not applicable
Explosive limit - lower (%)	Not applicable
Explosive limit - upper (%)	Not applicable
Vapor pressure	Not applicable
Vapor density	Not applicable
Relative density	Not applicable
Solubility(ies)	Not available.
Auto-ignition temperature	Not applicable
Decomposition temperature	Not applicable
Viscosity	Not applicable

10. Stability and Reactivity

Reactivity	None known.
-------------------	-------------

Possibility of hazardous reactions	No dangerous reaction known under conditions of normal use.
Chemical stability	Material is stable under normal conditions.
Conditions to avoid	Contact with incompatible materials, i.e strong oxidizing agents.
Incompatible materials	Strong oxidizing agents.
Hazardous decomposition products	Chlorine gas. Hydrogen chloride. Oxides of sodium.

11. Toxicological Information

Information on likely routes of exposure

Ingestion	Expected to be a low ingestion hazard.
Inhalation	No adverse effects due to inhalation are expected.
Skin contact	No adverse effects due to skin contact are expected.
Eye contact	Direct contact with eyes may cause temporary irritation.

Symptoms related to the physical, chemical and toxicological characteristics Direct contact with eyes may cause temporary irritation.

Information on toxicological effects

Acute toxicity	Not classified.
Skin corrosion/irritation	Prolonged skin contact may cause temporary irritation.
Exposure minutes	Not available.
Erythema value	Not available.
Oedema value	Not available.
Serious eye damage/eye irritation	Direct contact with eyes may cause temporary irritation.
Corneal opacity value	Not available.
Iris lesion value	Not available.
Conjunctival reddening value	Not available.
Conjunctival oedema value	Not available.
Recover days	Not available.

Respiratory or skin sensitization

Respiratory sensitization	Not available.
Skin sensitization	This product is not expected to cause skin sensitization.

Germ cell mutagenicity No data available to indicate product or any components present at greater than 0.1% are mutagenic or genotoxic.

Mutagenicity No data available to indicate product or any components present at greater than 0.1% are mutagenic or genotoxic.

Carcinogenicity This product is not considered to be a carcinogen by IARC, ACGIH, NTP, or OSHA.

Reproductive toxicity This product is not expected to cause reproductive or developmental effects.

Teratogenicity Not classified.

Specific target organ toxicity - single exposure Not classified.

Specific target organ toxicity - repeated exposure Not classified.

Aspiration hazard Not classified.

Chronic effects Not classified.

Further information This product has no known adverse effect on human health.

Name of Toxicologically Synergistic Products Not available.

12. Ecological Information

Ecotoxicity	The product is not classified as environmentally hazardous. However, this does not exclude the possibility that large or frequent spills can have a harmful or damaging effect on the environment.
Persistence and degradability	No data is available on the degradability of this product.
Bioaccumulative potential	No data available.
Mobility in soil	No data available.

Mobility in general	Not available.
Other adverse effects	No other adverse environmental effects (e.g. ozone depletion, photochemical ozone creation potential, endocrine disruption, global warming potential) are expected from this component.

13. Disposal Considerations

Disposal instructions	Collect and reclaim or dispose in sealed containers in accordance with applicable regulations.
Local disposal regulations	Dispose in accordance with all applicable regulations.
Hazardous waste code	The waste code should be assigned in discussion between the user, the producer and the waste disposal company.
Waste from residues / unused products	Dispose of in accordance with local regulations. Empty containers or liners may retain some product residues. This material and its container must be disposed of in a safe manner (see: Disposal instructions).
Contaminated packaging	Empty containers should be taken to an approved waste handling site for recycling or disposal. Since emptied containers may retain product residue, follow label warnings even after container is emptied.

14. Transport Information

U.S. Department of Transportation (DOT)	Not regulated as dangerous goods.
Transportation of Dangerous Goods (TDG - Canada)	Not regulated as dangerous goods.

15. Regulatory Information

Canadian federal regulations	This product has been classified in accordance with the hazard criteria of the Controlled Products Regulations and the SDS contains all the information required by the Controlled Products Regulations.
WHMIS status	Not Controlled
US federal regulations	
TSCA Section 12(b) Export Notification (40 CFR 707, Subpt. D)	Not regulated.
CERCLA Hazardous Substance List (40 CFR 302.4)	Not listed.
Clean Air Act (CAA) Section 112(r) Accidental Release Prevention (40 CFR 68.130)	Not regulated.
Clean Air Act (CAA) Section 112 Hazardous Air Pollutants (HAPs) List	Not regulated.
Superfund Amendments and Reauthorization Act of 1986 (SARA)	
Hazard categories	Immediate Hazard - No Delayed Hazard - No Fire Hazard - No Pressure Hazard - No Reactivity Hazard - No
SARA 302 Extremely hazardous substance	No
SARA 311/312 Hazardous chemical	No
SARA 313 (TRI reporting)	Not regulated.
Other federal regulations	
Safe Drinking Water Act (SDWA)	Not regulated.
Food and Drug Administration (FDA)	Not regulated.
US state regulations	
California Safe Drinking Water and Toxic Enforcement Act of 1986 (Proposition 65): This material is not known to contain any chemicals currently listed as carcinogens or reproductive toxins.	
US - California Proposition 65 - Carcinogens & Reproductive Toxicity (CRT): Listed substance	
Not listed.	
US. Massachusetts RTK - Substance List	
Not regulated.	
US. Pennsylvania RTK - Hazardous Substances	
Not regulated.	

US. Rhode Island RTK

Not regulated.

Inventory status

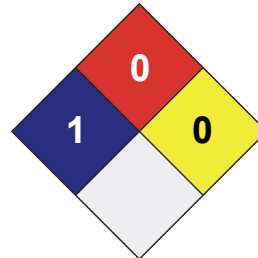
Country(s) or region	Inventory name	On inventory (yes/no)*
Canada	Domestic Substances List (DSL)	Yes
Canada	Non-Domestic Substances List (NDSL)	No
United States & Puerto Rico	Toxic Substances Control Act (TSCA) Inventory	Yes

*A "Yes" indicates that all components of this product comply with the inventory requirements administered by the governing country(s)

16. Other Information

LEGEND	
Severe	4
Serious	3
Moderate	2
Slight	1
Minimal	0

HEALTH	/ 1
FLAMMABILITY	0
PHYSICAL HAZARD	0
PERSONAL PROTECTION	X

**Disclaimer**

The information in the sheet was written based on the best knowledge and experience currently available. Information contained herein was obtained from sources considered technically accurate and reliable. While every effort has been made to ensure full disclosure of product hazards, in some cases data is not available and is so stated. Since conditions of actual product use are beyond control of the supplier, it is assumed that users of this material have been fully trained according to the requirements of all applicable legislation and regulatory instruments. No warranty, expressed or implied, is made and supplier will not be liable for any losses, injuries or consequential damages which may result from the use of or reliance on any information contained in this document.

Issue date

29-August-2014

Effective date

01-August-2014

Expiry date

01-August-2017

Further information

Not available.

Prepared by

Dell Tech Laboratories, Ltd. Phone: (519) 858-5021

Other information

This Safety Data Sheet was prepared to comply with the current OSHA Hazard Communication Standard (HCS) adoption of the Globally Harmonized System of Classification and Labeling of Chemicals (GHS).

This SDS conforms to the ANSI Z400.1/Z129.1-2010 Standard.