



**UHD
FORMULA**

ULTRA
HIGH
DEFINITION

THE ULTIMATE PAPER
TECHNOLOGY WITH
A SPECIAL SURFACE
TREATMENT

Make your work stand out



Bright white paper

Excellent print contrast and dazzling color for premium-quality color documents.

Extra smooth

Microporous surface for fast ink drying and accurate absorption, ensuring high-definition images.

Extra thick and opaque

Prevents print show-through and sheet waviness while ensuring accurate character definition.

20lb

8 1/2 x 11" | 8 1/2 x 13"
8 1/2 x 14" | 11 x 17" | A4

Fast drying surface, ideal for printing

Reports, Memos, Color Graphics, Data Tables and more.



OPTIMAL COLOR
CONTRAST



FAST
DRYING



ACCURATE
ABSORPTION




DATA TABLES



GRAPHICS

Ideal for charts and rich color graphics

Navigator Platinum Digital is one of the whitest office papers available in the market, making it especially suitable for color printing with any type of document.

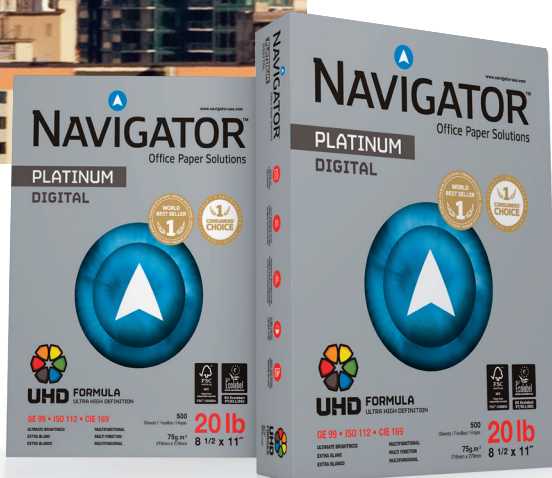

NAVIGATOR[™]
PLATINUM  DIGITAL



Extra smooth with a microporous surface


Superior print quality

Navigator Platinum Digital's even sheet formation and porosity guarantee uniform ink/toner application onto the paper surface, while its stunning whiteness increases print contrast.

Plus, its specially treated surface ensures optimum ink-paper interaction and better toner adhesion. And its excellent opacity prevents show-through in duplex printing applications.

Perfect images guaranteed

With lower ink consumption

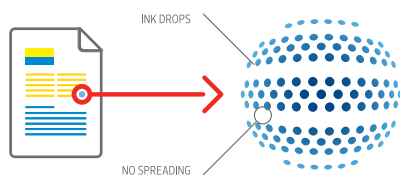

Best performance

Navigator Platinum Digital's ideal thickness/stiffness ratio reduces waste through paper jamming, misfeeding and multifeeding.

Its absolute and relative humidity levels are controlled to provide optimum post-printing flatness, minimizing curl.

Navigator Platinum Digital ensures high cutting quality—perfect for stable, trouble-free larger print runs.

Extra thick and opaque paper

NO SHOW THROUGH OR WAVINESS



ACCURATE CHARACTER DEFINITION

For best results use the following settings in your printer setup:

1 Select "Plain" paper type. 2 Select "Better" printing quality. 3 Adjust color saturation and tone for enhanced images. See your Printer Manual for further instructions.

20lb

Size	Item #	Brightness	Ctns/Pallet	Thickness µm	Caliper	Opacity	M-Wgt	Sheets/Ctn
8 1/2 x 11	NPL1120	99	40	105	4.13	93	10	5,000
8 1/2 x 11	NPL11205R	99	70	105	4.13	93	10	2,500
8 1/2 x 14	NPL1420	99	30	105	4.13	93	12.72	5,000
11 x 17	NPL1720	99	40	105	4.13	93	20	2,500
8 1/2 x 11	NPL11FP	99	70	105	4.13	93	10	2,500
8 1/2 x 11	NPLFP3H	99	70	105	4.13	93	10	2,500
A4	NPLA4	99	40	105	4.13	93	10	5,000



Navigator's unique UHD formula translates into a special surface treatment that maintains the color pigment near the surface, ensuring top definition with vivid colors, sharp contrasts and fast drying.



The mark of responsible forestry



EU Ecolabel: PT/011/002