



FS-HIVIS185

Reflective Full Body Harness : 1D, MB Chest, TB Legs

FEATURES :


- Dorsal D-ring
- Mating buckle chest
- Friction buckle torso adjusters
- Tongue buckle legs
- Shoulder pad
- Hi-vis reflective webbing

FALL ARREST POINT(S) :

- 1 Dorsal D-ring

ITEM WEIGHT :

- 3.0 lbs. (1.4 kg)

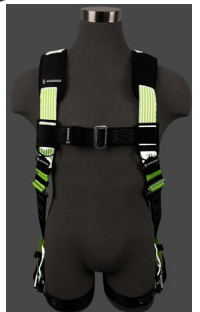

ABOVE: Front and Back of Harness
 RIGHT: Front of Harness in the dark with flash photography to show reflective web quality

USER WEIGHT CAPACITY	
ANSI	130-310 lbs. (59-140.6 kg)
OSHA	Up to 420 lbs. (190.5 kg)

STANDARD COMPLIANT WITH	
ANSI	Z359.11-2021, 107-2021
OSHA	1926.502, 1910.140

SIZE(S)	
FS-HIVIS185-S/M	Small / Medium
FS-HIVIS185-SL/XL	Large / X-Large
FS-HIVIS185-2X	2X

COMPONENT	MATERIAL SPECIFICATION
Webbing	Hi-vis polyester
D-ring	Zinc plated alloy steel
Adjuster buckles	Zinc plated alloy steel
Chest connection	Zinc plated alloy steel
Leg connection	Steel tongue buckle w/ SS grommets
Pad	Polyester mesh; EVA