


TRANSFORMER

LT150-120

Transformer, 150VA 480/277/240/208 to 120 Vac, Foot and Dual Threaded Hub Mount, Circuit Breaker

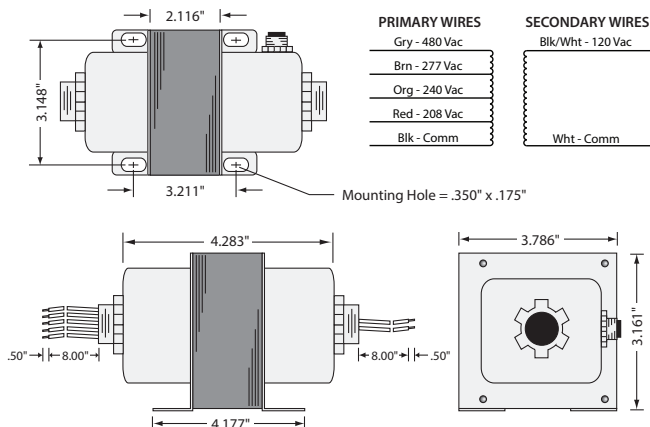

SPECIFICATIONS

- VA Rating:** 150
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hub
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.161" H x 3.786" W x 4.283" D (w/ .500" NPT Hubs)
- Wire Length:** 8" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Approvals:** UL5085-2 Listed General Purpose, C-UL, CE, RoHS