

JACKSON^{*}
SAFETY Brand

KleenGuard^{*}
BRAND

Industrial Manufacturing Safety Solutions

In Industrial Manufacturing, keeping employees protected requires constant attention.

At Kimberly-Clark Professional^{*}, we are committed to helping make your facility healthier, safer and more productive. With brands like KleenGuard^{*} and Jackson Safety^{*}, Kimberly-Clark Professional^{*} is committed to providing the right products to help keep your employees safe.

Selecting the right apparel, eye protection and gloves is a key to keeping your employees safe and keeping your operation in motion.

With our Industrial Manufacturing Safety Solutions bundle, Kimberly-Clark Professional^{*} has you covered.



 **Kimberly-Clark**
PROFESSIONAL^{*}

Industrial Manufacturing Task Map

Fabrication/Welding

Task:

Cutting, forming, joining

Main Hazards:

Eye: impact, IRUV, radiation

Hand: cut, abrasion

Hearing: noise exposure

Respiratory: particulate

Surface Preparation

Task:

Grinding, cleaning, applying solvents, thinners, lubricants, and adhesives

Main Hazards:

Skin: particulate exposure, liquid exposure

Eye: impact, liquid splash, particulates, IRUV

Hand: chemical, cut, abrasion

Hearing: noise exposure

Respiratory: particulate

Maintenance & Repair

Task:

Preventative maintenance, cleaning

Main Hazards:


Skin: liquid exposure


Eye: impact, liquid splash, particulates, IRUV, radiation

Hand: chemical, cut, abrasion

Hearing: noise exposure

Respiratory: particulate

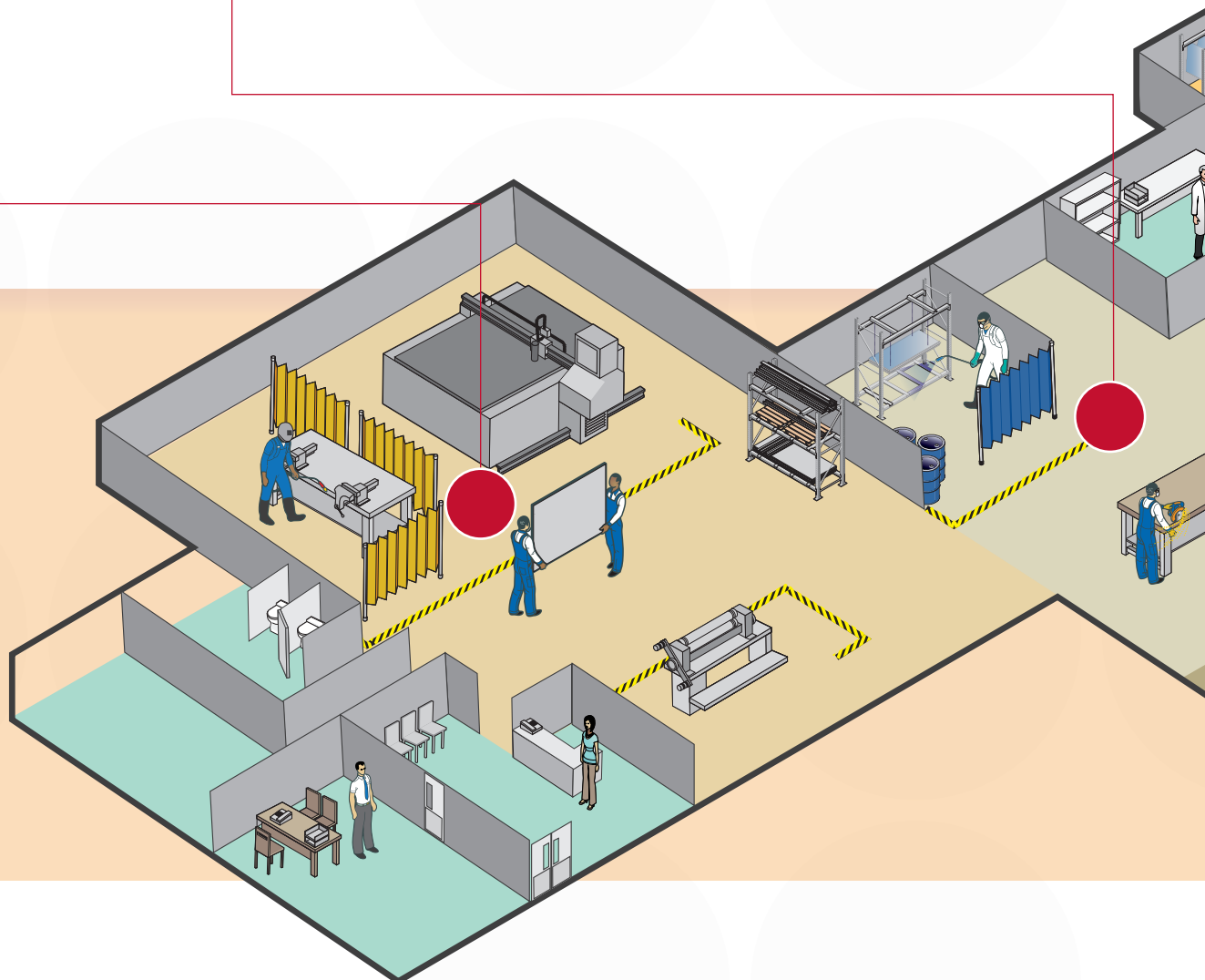

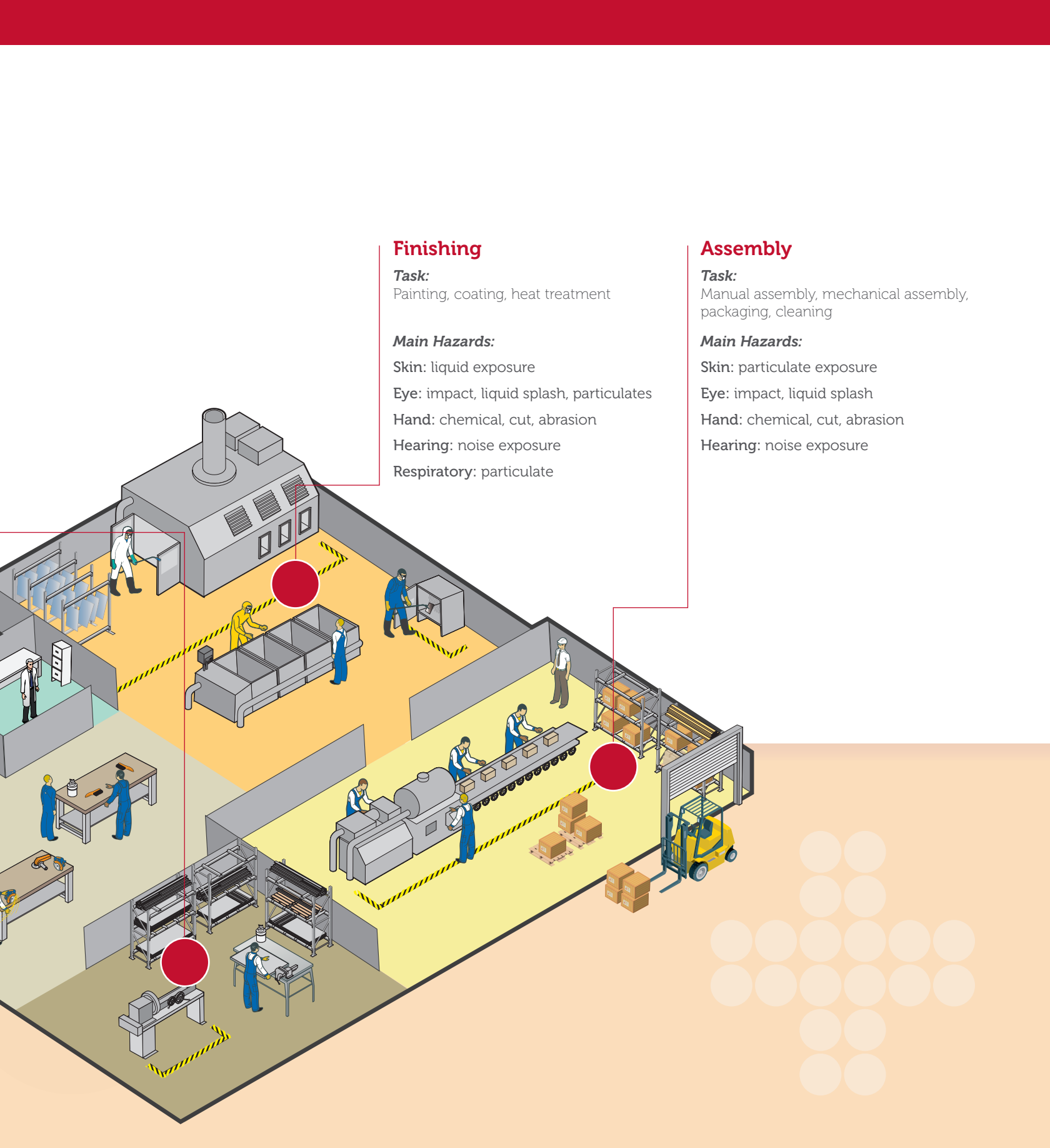

Finishing

Task:

Painting, coating, heat treatment

Main Hazards:

Skin: liquid exposure

Eye: impact, liquid splash, particulates

Hand: chemical, cut, abrasion

Hearing: noise exposure

Respiratory: particulate

Assembly

Task:

Manual assembly, mechanical assembly, packaging, cleaning

Main Hazards:

Skin: particulate exposure

Eye: impact, liquid splash

Hand: chemical, cut, abrasion

Hearing: noise exposure

Personal Protective Equipment Solutions

Fabrication/Welding

Cutting, forming, joining

Eyewear Solutions:

Jackson Safety* Nemesis*
Safety Eyewear

Jackson Safety* Calico*
Safety Eyewear

Jackson Safety* V90
Shield Protection

Glove Solutions:

Jackson Safety* G40
Polyurethane Coated Gloves

Jackson Safety* G60 L3
Purple Nitrile* Cut Resistant Gloves
G60 Level 3 Economy Cut Gloves

Hearing Protection Solutions:

Jackson Safety* H10
Disposable Earplugs

Respirator Solutions:

Jackson Safety* R10 N95 Particulate
Respirator with Comfort Straps

Jackson Safety* R20 P95 OV
Particulate Respirator with
Comfort Straps and Dual Valves

Welding Solutions:

Jackson Safety* InSight* HLX
Welding Helmet with Variable ADF
Jackson Safety* Airmax Elite* PAPR
with BH3* Air Headpiece

Surface Preparation

Grinding, cleaning, applying solvents,
thinners, lubricants, and adhesives

Apparel Solutions:

KleenGuard* A20 Coveralls

KleenGuard* A45 Coveralls

Eyewear Solutions:

Jackson Safety* Nemesis* Safety Eyewear

Jackson Safety* Calico* Safety Eyewear

Jackson Safety* Wildcat* Safety Goggles

Jackson Safety* V90 Shield Protection

Glove Solutions:

KleenGuard* G10 Blue Nitrile Gloves

Jackson Safety* G40 Polyurethane
Coated Gloves

Jackson Safety* G60 L3

Purple Nitrile* Cut Resistant Gloves

Jackson Safety* G60 Level 3
Economy Cut Gloves

Jackson Safety* G80
Nitrile Chemical Resistant Gloves

Hearing Protection Solutions:

Jackson Safety* H10 Disposable Earplugs

Respirator Solutions:

Jackson Safety* R10 N95 Particulate
Respirator with Comfort Straps

Jackson Safety* R20 P95 OV Particulate
Respirator with Comfort Straps
and Dual Valves

Maintenance & Repair

Preventative maintenance,
cleaning

Apparel Solutions:

KleenGuard* A45 Coveralls

Eyewear Solutions:

Jackson Safety* Nemesis*
Safety Eyewear

Jackson Safety* Calico*
Safety Eyewear

Jackson Safety* Wildcat*
Safety Goggles

Jackson Safety* V90
Shield Protection

Glove Solutions:

Jackson Safety* G40
Polyurethane Coated Gloves

Jackson Safety* G60 L3

Purple Nitrile* Cut Resistant Gloves

Jackson Safety* G60 Level 3
Economy Cut Gloves

Jackson Safety* G80
Nitrile Chemical Resistant Gloves




Hearing Protection Solutions:

Jackson Safety* H10
Disposable Earplugs

Respirator Solutions:

Jackson Safety* R10 N95
Particulate Respirator with
Comfort Straps

Jackson Safety* R20 P95 OV
Particulate Respirator with Comfort
Straps and Dual Valves

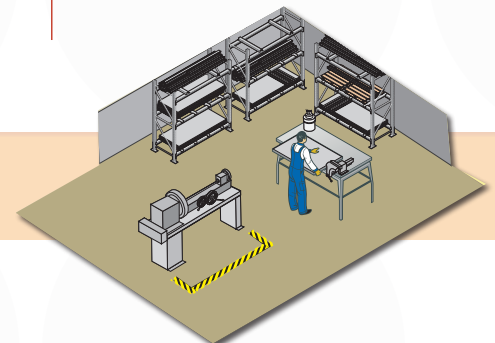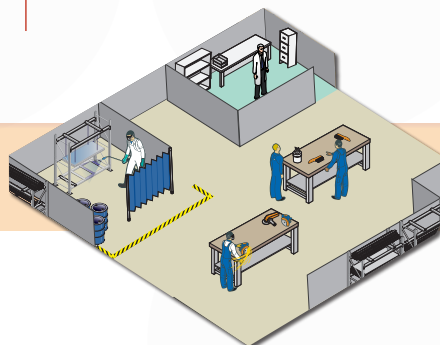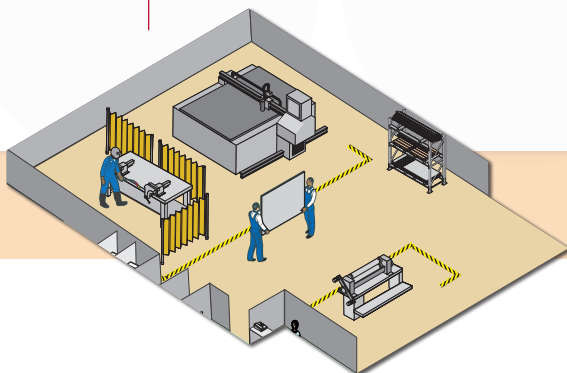

For additional product offerings please reference the Safety & Industrial Product Catalog at <http://www.kcprofessional.com/safetycatalog>

Finishing

Painting, coating,
heat treatment

Apparel Solutions:

KleenGuard* A45 Coveralls

Eyewear Solutions:

Jackson Safety* Nemesis*
Safety Eyewear

Jackson Safety* Calico*
Safety Eyewear

Jackson Safety* V90
Shield Protection

Glove Solutions:

KleenGuard* G10
Blue Nitrile Gloves

Jackson Safety* G40
Polyurethane Coated Gloves

Jackson Safety* G60 L3
Purple Nitrile* Cut Resistant Gloves

Jackson Safety* G60 Level 3
Economy Cut Gloves

Jackson Safety* G80
Nitrile Chemical Resistant Gloves

Hearing Protection Solutions:

Jackson Safety* H10
Disposable Earplugs

Respirator Solutions:

Jackson Safety* R10 N95 Particulate
Respirator with Comfort Straps

Jackson Safety* R20 P95 OV Particulate
Respirator with Comfort Straps
and Dual Valves

Assembly

Manual assembly, mechanical
assembly, packaging, cleaning

Apparel Solutions:

KleenGuard* A20 Coveralls

Eyewear Solutions:

Jackson Safety* Nemesis*
Safety Eyewear

Jackson Safety* Wildcat*
Safety Goggles

Jackson Safety* V90
Shield Protection

Glove Solutions:

KleenGuard* G10
Blue Nitrile Gloves



Jackson Safety* G40
Polyurethane Coated Gloves

Jackson Safety* G60 L3
Purple Nitrile Cut Resistant Gloves

Jackson Safety* G60 Level 3
Economy Cut Gloves

Hearing Protection Solutions:

Jackson Safety* H10
Disposable Earplugs

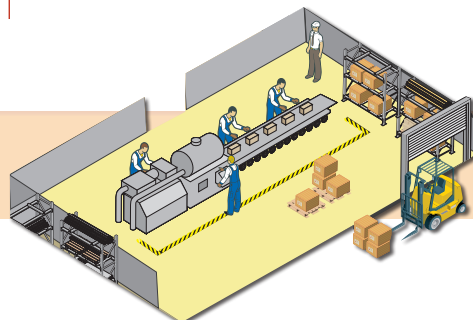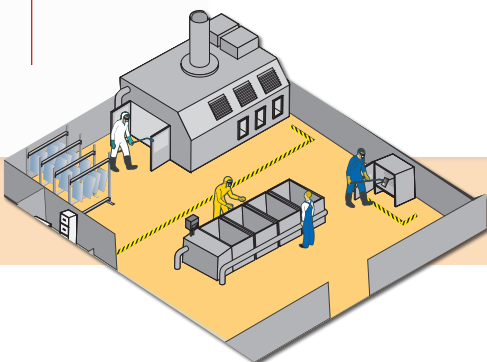

JACKSON*
SAFETY BRAND

KleenGuard*
BRAND

KleenGuard* A20 Coveralls Available in White and Denim Blue



Zippered Front	White Code	Blue Denim Code	Size	Case Count	Product Features
	49002	58532	M	24	<ul style="list-style-type: none"> • Reflex* Coverall Design offers excellent fit and freedom of movement • Seamless front provides more protection in the primary exposure area • Breathable, patented Microforce* Barrier SMMMS fabric blocks particles from penetrating garment • Passes NFPA 99 for antistatic materials • Serged seams
	49003	58533	L	24	
	49004	58534	XL	24	
	49005	58535	2XL	24	
	49006	58536	3XL	20	
	49007	58537	4XL	20	

KleenGuard* A45 Coveralls



Zippered Front, Elastic Wrists, Ankles & Hood	Code	Size	Case Count	Product Features
	41503	S	25	<ul style="list-style-type: none"> • Protects against isocyanates¹ • Protects against chromate dust • Silicone-free² • Reflex* Coverall Design offers excellent fit and freedom of movement • Passes NFPA 99 for antistatic materials
	41504	M	25	
	41505	L	25	
	41506	XL	25	
	41507	2XL	25	
	41508	3XL	25	
	41509	4XL	25	

¹ Tested against polyurethane containing polymeric isocyanate (40% concentration) ² Per BMS 15-5G Method 2611 and AMS 3819C, 1% detection limit

Jackson Safety* Nemesis* Eyewear • Pairs/Box: 12



Code	Lens	Coating	Frame	Gravity Feed	Product Features
25676	Clear		Black		<ul style="list-style-type: none"> • Sporty, flexible, and lightweight design for comfort and compliance • Enhanced nosepiece design with integrated ridges to divert sweat • Hardcoated lenses for scratch resistance and longer life
25679	Clear	Anti-Fog	Black		
25659	Amber		Black		
22476	Amber	Anti-Fog	Black		
25692	IRUV Shade 3.0		Black		
25671	IRUV Shade 5.0		Black		

Nemesis* with RX Inserts Safety Eyewear • Pairs/Box: 12



Code	Lens	Coating	Frame	Gravity Feed	Product Features
38503	Clear	Anti-Fog	Black		<ul style="list-style-type: none"> • Sporty eyewear that comes with a close-fit prescription lens insert behind the polycarbonate eye shield • Adjustable ratchet-action temples with five positions provide a customized fit
38504	Amber	Anti-Fog	Black		

Insight* Digital Variable ADF Welding Helmet

Code	Description	Units/Case	Product Features
46131	HLX 100 Welding Helmet with Insight* Variable ADF – Black	1	<ul style="list-style-type: none"> • Variable shade 9-13 • Sensitivity and delay adjustments • Meets ANSI Z87.1–2010 standards and CSA compliant

Airmax Elite* Powered Air Purifying Respirator with BH3* Air Headtop

Code	Description	Units/Case	Product Features
40839	Airmax Elite* PAPR with BH3* Air Headtop	1	<ul style="list-style-type: none"> • Variable ADF with grind mode. Adjustable shades 6-8 (grind) and 9-13 via external knob • NIOSH 42 and CFR Part 84 certified

Key

TAA: Product complies with the Trade Agreements Act

Meets Canadian requirements and U.S. FDA regulations for **food handling** applications

D3: Meet the ANSI D3 requirements for protecting from liquid splashes or droplets

The RightCycle Program by Kimberly-Clark Professional*

UV: Lenses are made of a polycarbonate material that provides 99.9% UVA/UVB/UVC protection

D4: Meet the ANSI D4 requirements for dust protection

KleenGuard* G10 Blue Nitrile Gloves



Code	Vending	Color	Size	Case Count
57370	42609	Blue	6 (XS)	100 gloves/box • 10 boxes/case
57371	42610	Blue	7 (S)	100 gloves/box • 10 boxes/case
57372	41071	Blue	8 (M)	100 gloves/box • 10 boxes/case
57373	41078	Blue	9 (L)	100 gloves/box • 10 boxes/case
57374	41059	Blue	10 (XL)	90 gloves/box • 10 boxes/case

- Product Features**
- 6 mil; 9.5" length
 - Light chemical splash protection
 - Touchscreen compatible
 - Textured fingertips; powder-free

Jackson Safety* G40 Polyurethane Coated Gloves



Code	Color	Size	Case Count
13837	Black	7 (S)	12 pairs/bag • 5 bags/case
13838	Black	8 (M)	12 pairs/bag • 5 bags/case
13839	Black	9 (L)	12 pairs/bag • 5 bags/case
13840	Black	10 (XL)	12 pairs/bag • 5 bags/case
13841	Black	11 (2XL)	12 pairs/bag • 5 bags/case

- Product Features**
- Thin mil feel for tactile sensitivity
 - Excellent grip and dexterity
 - Abrasion-resistant

Jackson Safety* G60 Level 3 Purple Nitrile* Cut Resistant Gloves



Code	Color	Size	Case Count
13844	Grey & Black w/Purple Tips	6 (XS)	12 pairs/bag • 1 bag/case
97430	Grey & Black w/Purple Tips	7 (S)	12 pairs/bag • 1 bag/case
97431	Grey & Black w/Purple Tips	8 (M)	12 pairs/bag • 1 bag/case
97432	Grey & Black w/Purple Tips	9 (L)	12 pairs/bag • 1 bag/case
97433	Grey & Black w/Purple Tips	10 (XL)	12 pairs/bag • 1 bag/case
97434	Grey & Black w/Purple Tips	11 (2XL)	12 pairs/bag • 1 bag/case

- Product Features**
- Ambidextrous
 - Dots on palm enhance grip
 - ANSI Level 3/EN388 Level 3 cut resistance; CPPT = 1,150 grams

Jackson Safety* G60 Level 3 Economy Cut Gloves†



Code	Color	Size	Case Count
38689	Black & White	7 (S)	12 pairs/bag • 1 bag/case
38690	Black & White	8 (M)	12 pairs/bag • 1 bag/case
38691	Black & White	9 (L)	12 pairs/bag • 1 bag/case
38692	Black & White	10 (XL)	12 pairs/bag • 1 bag/case
38693	Black & White	11 (2XL)	12 pairs/bag • 1 bag/case

- Product Features**
- ANSI Level 2/EN388 Level 3 cut resistance
 - CPPT = 686 grams
 - Ultra-High-Molecular-Weight Polyethylene (UHMWPE) yarn with nylon and Lycra® fiber provides cut resistance and a comfortable fit
 - Black polyurethane coating enhances grip
 - Dark coating hides dirt for longer wear

† CAUTION: This Product Contains Natural Rubber Latex Which May Cause Allergic Reactions.

Jackson Safety* G80 Nitrile Chemical Resistant Gloves



Code	Color	Size	Case Count
94445	Green	7 (S)	12 pairs/bag • 5 bags/case
94446	Green	8 (M)	12 pairs/bag • 5 bags/case
94447	Green	9 (L)	12 pairs/bag • 5 bags/case
94448	Green	10 (XL)	12 pairs/bag • 5 bags/case
94449	Green	11 (2XL)	12 pairs/bag • 5 bags/case

- Product Features**
- Cotton flock lined for added comfort
 - 15 mil thickness; 13" length
 - Textured fingertips enhance grip
 - Meets EN374-3: 2003 standard
 - Meets Canadian requirement and U.S. FDA regulations for food handling applications

Jackson Safety* H10 Disposable Earplugs



Code	Description	NRR	Class	Case Count
67210	Uncorded	31	A(L)	200 Pairs/Box; 8 Boxes/Case

- Product Features**
- Soft roll-down foam
 - Smooth "bullet" shape for easy insertion
 - High visibility for easy compliance monitoring

Z87.1+ Meet the ANSI requirements for high-impact protection

CSA: Certified to meet the requirements of CSA Z94.3

BASE CURVE 10 Base Curve: Number denotes the base curve of the eyewear; a higher base curve provides more wraparound protection and peripheral vision, and can reduce the need for side shields

JACKSON
SAFETY BRAND

KleenGuard
BRAND

Jackson Safety* R20 P95 OV Particulate Respirator with Comfort Straps and Dual Valves



Code	Description	Protection	Case Count	Valve Color	Product Features
64560	P95 Particulate Respirator with Dual Valves and Nuisance Level Organic Vapor Relief	P95	10/box 8 boxes/case	Yellow	<ul style="list-style-type: none"> Effective against all oil based and non-oil based particulate aerosols and dust that do not emit harmful vapors Carbon layer reduces exposure to nuisance levels of organic vapors

Jackson Safety* R10 N95 Particulate Respirator with Comfort Straps



Code	Description	Protection	Case Count	Strap Color	Product Features
64250	N95 Particulate Respirator with Comfort Straps	N95	20/box 8 boxes/case	Blue	<ul style="list-style-type: none"> Wide, comfortable, user-preferred head straps Adjustable head straps Soft, comfortable, foam nose pad with a cloth layer

Jackson Safety* Calico* Safety Eyewear



Code	Lens	Coating	Frame	Pairs/Box	Product Features
25672	Clear	Anti-Fog	Black	12	<ul style="list-style-type: none"> Temple straps can be interchanged with (included) head strap when a closer, more secure fit is required Removable foam lining provides long-term comfort and helps to seal out dust and debris Superior anti-scratch and anti-fog coating
25674	Amber	Anti-Fog	Black	12	

Jackson Safety* Wildcat* Goggle Protection



Code	Lens	Coating	Frame	Pairs/Box	Product Features
20525	Clear	Anti-Fog	Black	12	<ul style="list-style-type: none"> Splash and dust protection with a pliable frame and foam gasket – these goggles are designed for all-day comfort
20527	Amber	Anti-Fog	Black	12	
20528	IRUV Shade 3.0	Anti-Fog	Black	12	<ul style="list-style-type: none"> Extreme heat resistance, this eyewear will not melt, drip, or ignite at 350°F for five minutes
20529	IRUV Shade 5.0	Anti-Fog	Black	12	

Jackson Safety* Shield Goggle Protection



Code	Lens	Coating	Frame	Pairs/Box	Product Features
18629	Clear	Anti-Fog	Blue	6	<ul style="list-style-type: none"> Monogoggle* XTR goggles integrated into a face shield to provide full eye and face protection from liquids without the hassle of primary eye protection underneath a face shield
18631	IRUV Shade 3.0	Anti-Fog	Black	6	
18633	IRUV Shade 5.0	Anti-Fog	Black	6	

The following information is provided to assist with your buying decisions. Read all instructions and warnings attached to product before use.

It is the responsibility of the user to assess the types of hazards and the risks associated with exposure and then decide on the appropriate personal protective equipment needed for each circumstance. Failure to use only Jackson Safety* designed, produced and tested components, attachments and replacement parts can adversely affect product performance resulting in serious injury.

JACKSON SAFETY* AND KLEENGUARD* APPAREL AND HAND PROTECTION: Apparel or hand protection should be replaced immediately if ripped, torn, abraded or punctured. Fabrics are not flame-resistant unless specified. Keep away from sparks, flames and sources of ignition. Melting fabric can cause severe burns. The information provided within this literature refers to the performance of the fabric only, in the laboratory under controlled conditions. Kimberly-Clark makes no representation that its products will provide complete protection from exposure to contaminants. Thin mil gloves are for industrial use only, and are not intended for applications involving direct exposure to hazardous chemicals.

JACKSON SAFETY* EYE PROTECTION: Provides limited eye protection and may not protect you from all hazards. Additional protective devices may be required for full eye coverage and protection. Does not protect you from all hazards. Even though the lenses in these safety glasses are impact-resistant, they can break and shatter and will not protect you from explosions, all flying debris, and severe impacts. Should not be worn to provide protection from other hazards including, but not limited to, extreme temperatures, high heat, airborne dusts or mists, liquid splashes, sports activities and high-energy optical radiation.



Our Guarantee: Your total satisfaction means everything to us. If, for any reason, our products do not meet your expectations, Kimberly-Clark will reimburse you[†] for your initial purchase, via FREE product, for up to \$1,000.

For more information on Kimberly-Clark Professional*, visit us online at www.KCProfessional.com. [†] Guarantee extended to consuming end-user accounts only.

Kimberly-Clark warrants that its products (1) comply with K-C's standard specifications as of the delivery date to K-C's authorized distributors/direct purchasers and are warranted for the following periods from end-user's date of purchase (verified by valid sales receipt) (a) five years for Balder* Technology auto darkening filters; (b) two years for all other auto-darkening filters; and (c) one year for powered air-purifying respirators; (2) comply with all K-C labeling representations; and (3) are manufactured in compliance with all applicable federal, state, and local laws in effect at the time and place of manufacture of the products. **THIS WARRANTY IS IN LIEU OF ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE.** K-C is not liable for any kind of special, incidental, or consequential damages. K-C's liability for breach of contract, tort or other cause of action shall not exceed the product purchase price. Purchasers and users are deemed to have accepted the above warranty and limitation of liability, and cannot change the terms by verbal agreement or by any writing not signed by K-C. To the extent required by applicable law, K-C does not limit its liability for death/injury resulting from K-C's negligence.

Trademarks of Kimberly-Clark Worldwide, Inc. or its affiliates. Marques déposées de Kimberly-Clark Worldwide, Inc. ou de ses filiales. The Color Grey is a Trademark of KCWW. The Color Purple and Purple Nitrile are owned by Halyard Health or its affiliates and used under license. © KCWW. T62NPE 1/16