


# HSM SECURIO C14

## Personal shredder

Space saving, quiet and reliable



- Entry level personal/home office model designed for 1 to 3 users
- Also shreds credit and store cards
- Automatic start/stop via photo eye sensor
- Separate reverse button
- Folding safety element with contact protection
- Cutting rollers are V-TEK technology by HSM with specially hardened steel rollers that save valuable energy
- Handle recess on the top to empty waste with ease
- Automatic stop when the shredded material is removed
- Quiet operation sound minimizes noise development in the workplace
- Energy Management Control System Zero Power - does not consume any power in standby mode
- Anti-Jam Technology designed to easily and quickly reverse out paper in the event the machine is overloaded
- Uses an 11 gallon capacity shred bag; Part #HSM1310

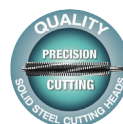

HSM Part#	HSM2250	HSM2253
Cutting type	Strip cut	Cross cut
Cutting size	1/8"	5/32" x 1"
Security level DIN 32757-1	2	3
Security level DIN 66399	P-2 / T-2 / E-2	P-4 / T-4 / E-3 / F-1
Cutting capacity per run in sheets	10 - 12	5 - 6
Cutting Speed	8.7 ft / min	8.7 ft / min
Throat opening	8.9"	8.9"
Motor at maximum no of sheets	300W	300W
Motor power (horsepower)	0.4 hp	0.4 hp
Voltage	115 V / 60Hz	115 V / 60Hz
Dimensions (H x W x D)	17.9" x 14.4" x 10.2"	17.9" x 14.4" x 10.2"
Weight	8.8 lbs	9.9 lbs
Shred-bin volume	5.3 gal	5.3 gal
Cutting capabilities		

All technical specifications are approximate values. Technical and design modifications reserved.

HSM of America, LLC  
 419 Boot Road  
 Downingtown, PA 19335  
 www.hsmofamerica.com  
 Customer Service: 800.613.2110

**HSM**<sup>®</sup>  
 Great Products, Great People.