


# Product data sheet

## Characteristics

# QO140M200P

Load center, QO, 1 phase, 40 spaces, 60 circuits, 200A convertible main breaker, NEMA1, UL

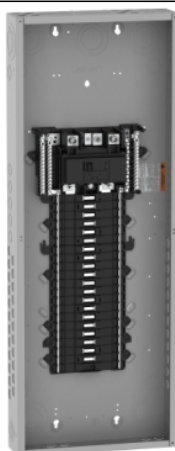

### Main

Marketing Trade Name	QO
Product Type	Load Center

### Complementary

Tightening Torque	Cover: 20 lb.in
Load Center Type	Main breaker
Rated Current	200 A
Number of Spaces	40
Max Short Circuit Current Rating	22 kA
Maximum Number of Single Pole Circuits	40
Maximum Number of Tandem Breakers	20
Number of Phases	1 phase
Ground Bar	Grounding bar (ordered separately)
Box Number	10
Height	33.78 in (858.01 mm)
Width	14.25 in (361.95 mm)
Depth	3.75 in (95.25 mm)

### Environment

Enclosure Rating	NEMA 1 for indoor
Ambient Air Temperature for Operation	23 °F (-5 °C) 104 °F (40 °C)
Product Certifications	UL Listed

### Ordering and shipping details

Category	10001 - QO PON 1PH LC,12-60 CKT, MB N1
Discount Schedule	DE3A
GTIN	00785901151142
Nbr. of units in pkg.	1
Package weight(Lbs)	1 lb(US) (0.45 kg)
Returnability	Yes
Country of origin	US

## Offer Sustainability

REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>

## Contractual warranty

Warranty	18 months
----------	-----------