



# SMART USB MONITOR

## EXPAND YOUR VIEW


- Smart LCD Monitor
- Supports Multi Monitor Mode
- Lightweight & Portable
- USB Video Input & Power
- No Video Card Needed
- PC & MAC Compatible




DoubleSight  
DISPLAYS

[www.doublesight.com](http://www.doublesight.com)

# SMART USB MONITOR

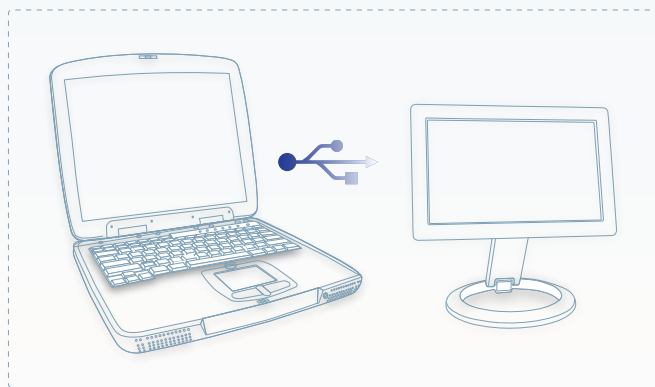

## APPLICATIONS

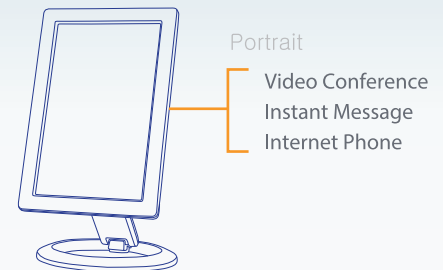

Model	DS-70U	DS-10U	DS-10UT
LCD Panel	7" Wide Screen	10.1" Wide Screen	10.1" Wide Screen
Resolution	800 x 480	1024 x 600	1024 x 600
Display Colors	16.7M	262K Colors	262K Colors
Brightness	375:1	200 cd / m2	200 cd / m2
Contrast Ratio	350:1	500:1	500:1
Viewing Angle	65/65/35/55	40/40/15/30	40/40/15/30
Response Time	30ms	16ms	16ms
Signal Input	USB 2.0 High Speed, no Video Card Required	USB 2.0 High Speed, no Video Card Required	USB 2.0 High Speed, no Video Card Required
Touch	N/A	N/A	Resistive
Connector	USB Mini 5-pin B Type	USB Mini 5-pin B Type	USB Mini 5-pin B Type
Power Input	USB Power	USB Power	USB Power
Power Consumption	3.3 ~ 4.9 W	3.3 ~ 4.9 W	3.3 ~ 4.9 W
Color	Black	Black	Black
Dimensions	7" W x 4.75 H x 1" deep (monitor only)	9.75" W x 6" H x .75" deep (monitor only)	9.75" W x 6" H x .75" deep (monitor only)
Weight	1 lb.	1.5 lb	1.5 lb
OS Support	Win 8.1(and below); MAC OSX 10.9(and below)	Win 8.1(and below); MAC OSX 10.9(and below)	Win 8.1(and below); MAC OSX 10.9(and below)
Warranty	3 year	3 year	3 year
Package Contents	USB Monitor	USB Monitor	USB Monitor with Touch Screen
	Adjustable Monitor Stand + Cover	Adjustable Monitor Stand	Adjustable Monitor Stand
	USB Cable	USB Cable	USB Cable
	Quick Installation Guide	Quick Installation Guide	Quick Installation Guide
	Driver and Users Manual on CD	Driver and Users Manual on CD	Driver and Users Manual on CD