



# DSLX



DOUBLE-SIDED LOCKABLE  
BALL LOCKER

## Features:

- 3/16" Heavy-duty Powder-coated Steel
- The Split Top Can Be Individually Locked
- Double Sided Ball Locker Allows For Divided Storage

## Instructions:

1. Combine the top & bottom panels together along with the side panels provided.
2. The front and back panels have a loop that will slide over the threaded studs on the side panels.
3. Place washers over the threaded studs on the end panels by pushing the threaded studs through the pre-punched holes in the "U" rail and secure with hex nuts. Do the same for the bent "U" rail on the other end panel.
4. Slide over the middle panel to the middle for separation.
5. Install the casters into the bottom holes of the "U" rail. Insert the wheel axle into the lower hole drilled on the bent "U" rail and attach the wheels.

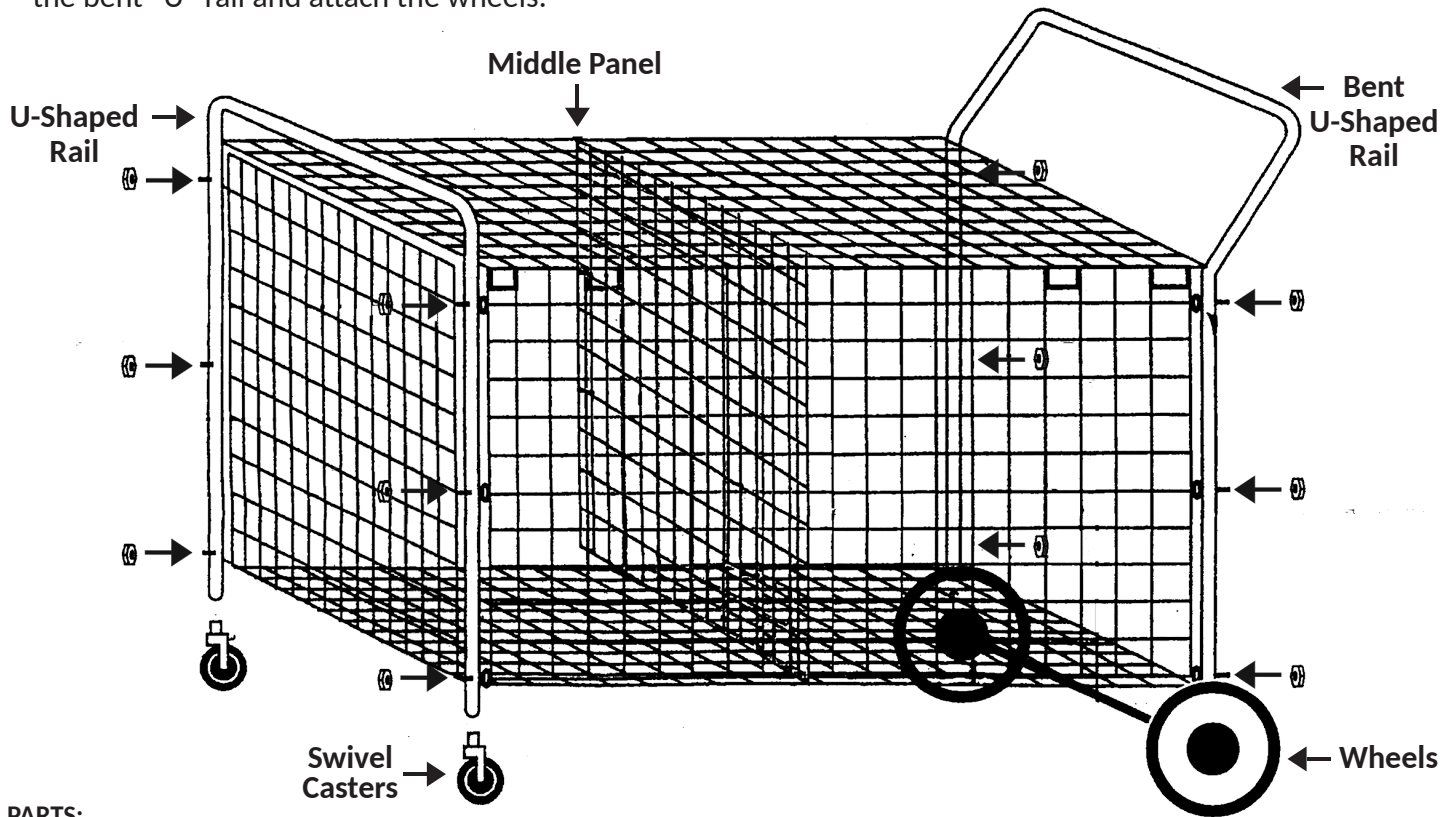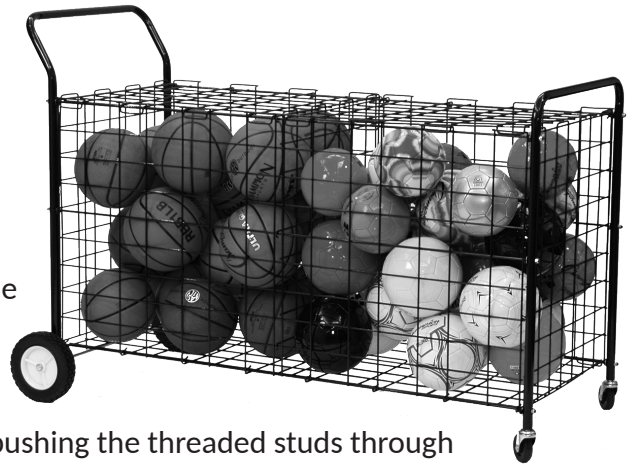

## PARTS:

- 1 U-Shaped Rail
- 1 Bent U-Shaped Rail
- 2 Wire Mesh Panels for Top & Bottom - 57" x 28.5"
- 2 Wire Mesh Panels for Sides - 24" x 28"
- 1 Wire Mesh Panel for Middle - 24" x 25.25"
- 4 Horizontal Rods for bottom
- 12 Nuts - 5/16"
- 12 Washers - 5/16"
- 2 Swivel Wheel Casters - 3"
- 2 Wheels w/axle - 8"