

PA730

Universal Articulating Wall Arm for 10"-29" Displays

It's easy to get the best viewing position when you can effortlessly pull out the display from the wall, position it in almost any direction, even turn it around corners and then smoothly return it to the wall when finished. Level the display at any time, even after installation, for that picture perfect end result. Never worry about cables and cords getting in the way; cable management delivers a clean clutter-free look to any installation.




Display size: 10"-29"



Max load: 25lb (11kg)

FEATURES

- Extends 14.46" (367mm) from the wall
- Retracts to 2.42" (61mm) to save space
- Integrated cable management keeps cables and cords out of the way
- One-Touch™ tilt mechanism offers $\pm 35^\circ$ of tilt angle adjustment
- $\pm 5^\circ$ of roll for post-installation display leveling
- Up to $\pm 90^\circ$ of swivel
- VESA® 75 and 100mm compliant
- UL listed

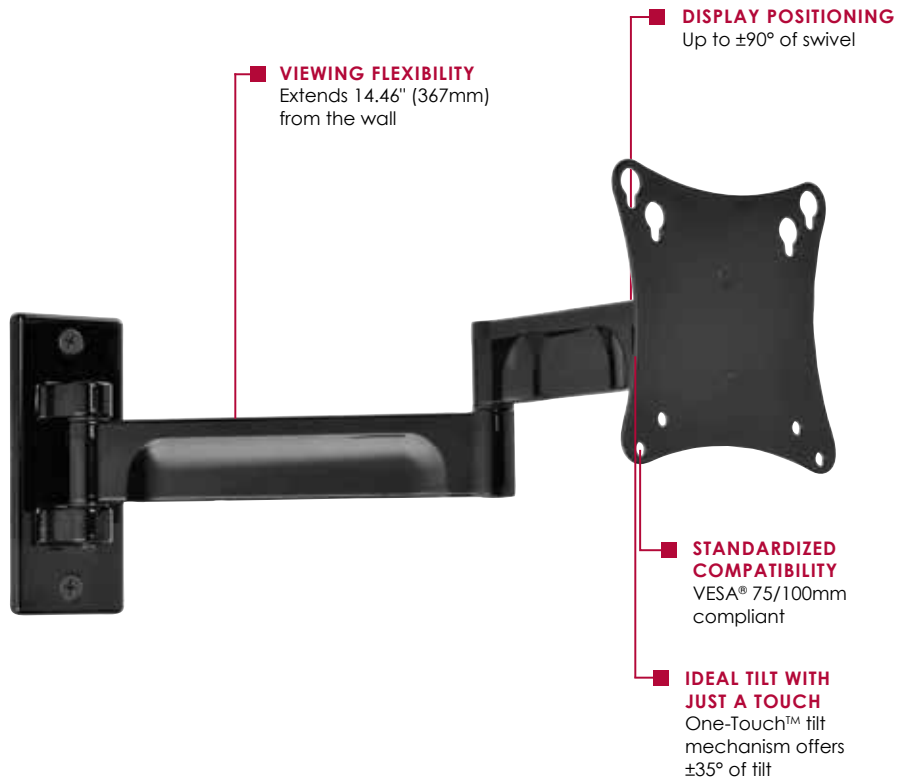

One-Touch™ tilt allows adjustment of $\pm 35^\circ$ without the use of tools



Integrated cable management



Patented. Design Patent No. D652,030; D636,765; D630,623.

CLICK: peerless-av.com

CALL: 800.865.2112

FAX: 800.359.6500

peerless-AV

PA730	Universal Articulating Wall Arm for 10"-29" Displays
--------------	--

Product Specifications

	DIMENSIONS (W x H x D)	PRODUCT WEIGHT	LOAD CAPACITY	FINISH	AVAILABLE COLORS
PA730	8.58" x 7.04" x 2.42"-14.46" (218 x 179 x 61-367mm)	1.35lb (.61kg)	25lb (11kg)	Scratch resistant fused epoxy	Gloss black


Package Specifications

	PACKAGE SIZE (W x H x D)	PACKAGE SHIP WEIGHT	PACKAGE UPC CODE	PACKAGE CONTENTS	UNITS IN PACKAGE
PA730	10.375" x 7.125" x 2.625" (264 x 181 x 67mm)	2.82lb (1.3kg)	735029255017	Mount with VESA® 75 and 100 adaptor plate, all necessary mounting and display attachment hardware	1

Accessories

- ACC918:** Security Fasteners
- WSP700:** Metal Stud Wall Plate for 16" Center Metal Studs
- WSP701:** Metal Stud Wall Plate for 20" and 24" Center Metal Studs

All dimensions = inch (mm)

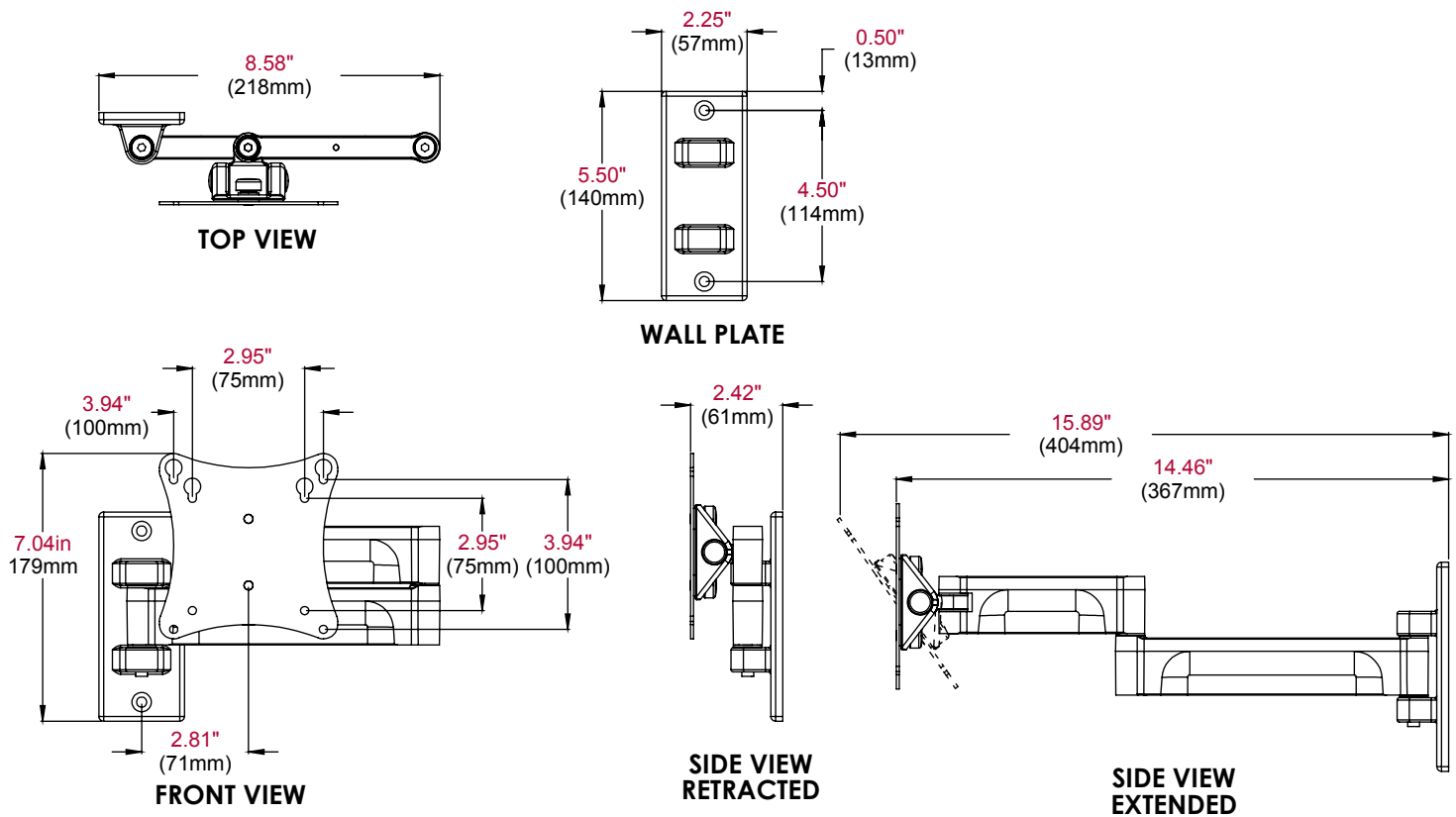

ARCHITECTS SPECIFICATIONS

The Universal Articulating Wall Arm shall be a Peerless-AV model PA730 and shall be located where indicated on the plans. It shall feature scratch resistant black or silver fused epoxy finish. Assembly and installation shall be done according to instructions provided by the manufacturer.