

### PORTSMOUTH 30" VANITY

#### 9210.030

- Transitional style vanity
- Constructed of poplar solids and birch veneers
- Matching Rattan door insert
- Slide-out step-up feature
- Storage area includes one shelf
- Available in a Dark Chocolate or White finish

#### Nominal Dimensions:

30" x 21-1/2" (762 x 546mm)

33-1/2" height (851mm)




#### To Be Specified (Required):


- ❑ 0615.000 Portsmouth vitreous china undercounter sink (White - 020) Use with laminated marble top (supplied by others).

or


- ❑ 7820.400 Portsmouth Fire Clay Vanity Top, with faucet holes on 4" (102mm) centers
- ❑ 7820.800 Portsmouth Fire Clay Vanity Top, with faucet holes on 8" (203mm) centers

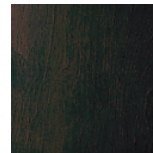

Dark Chocolate  
322

 

White  
020

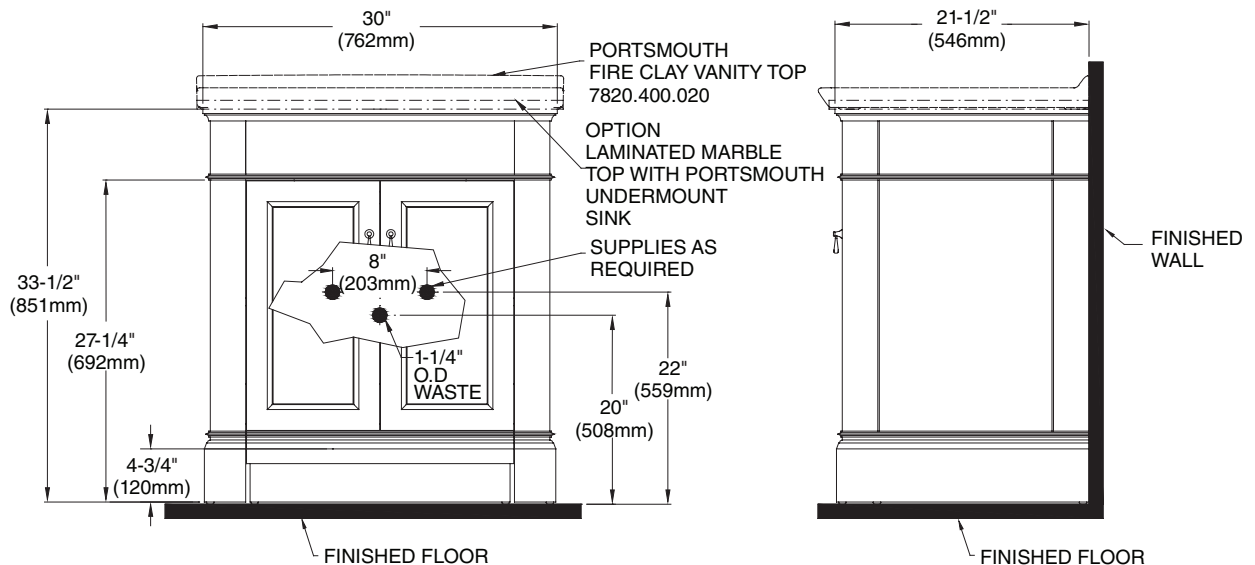

#### NOTES:

\* DIMENSIONS SHOWN FOR LOCATION OF SUPPLIES AND "P" TRAP ARE SUGGESTED.

▼ ANCHOR SCREWS FOR LAVATORY AND PEDESTAL NOT INCLUDED.

- FITTINGS NOT INCLUDED AND MUST BE ORDERED SEPARATELY.  
PROVIDE SUITABLE REINFORCEMENT FOR ALL WALL SUPPORTS.

**IMPORTANT:** Dimensions of fixtures are nominal and may vary within the range of tolerances established by ANSI Standard A112.19.9M. These measurements are subject to change or cancellation. No responsibility is assumed for use of superseded or voided pages.