

Features

- For use with a handshower and hose (sold separately).
- Coordinates with other products in the Exhale collection.

Material

- Metal construction.
- KOHLER finishes resist corrosion and tarnishing.

Installation

- Wall-mount.
- Easy installation using slip-fit connection.
- Includes 1218069 supply adapter.
- May require other adapter based on installation type (sold separately).



Adapters, Rough-in and Extension Kits

| | |
|---------|---|
| 1229031 | Range: 0" (0 mm) - 1/2" (13 mm) |
| 1247986 | Range: 5/16" (8 mm) - 13/16" (21 mm) |
| 1247985 | Range: 13/16" (21 mm) - 1-5/16" (33 mm) |
| 1247984 | Range: 1-5/16" (33 mm) - 1-13/16" (46 mm) |
| 1218070 | Range: 2-5/16" (59 mm) - 2-13/16" (71 mm) |
| 1218071 | Range: 2-13/16" (71 mm) - 3-5/16" (84 mm) |

Recommended Products/Accessories

K-23723 Faucet cleaner

Included Components

Product consists of:

1218069 Supply Adapter ASM-1.813-2.313 Rough-In

Codes/Standards






ASME A112.18.1/CSA B125.1

KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.


Available Colors/Finishes

Color tiles intended for reference only.

| Color | Code | Description |
|---|------|--------------------------------|
|  | CP | Polished Chrome |
|  | SN | Vibrant® Polished Nickel |
|  | BN | Vibrant® Brushed Nickel |
|  | 2MB | Vibrant® Brushed Moderne Brass |
|  | TT | Vibrant Titanium |

| Supply Adapter | A |
|--------------------|------------------------------------|
| 1218069 (included) | 1-13/16" – 2-5/16" (46 mm – 59 mm) |
| 1229031* | 0 – 1/2" (0 – 13 mm) |
| 1247986* | 5/16" – 13/16" (8 mm – 21 mm) |
| 1247985* | 13/16" – 1-5/16" (21 mm – 33 mm) |
| 1247984* | 1-5/16" – 1-13/16" (33 mm – 46 mm) |
| 1218070* | 2-5/16" – 2-13/16" (59 mm – 71 mm) |
| 1218071* | 2-13/16" – 3-5/16" (71 mm – 84 mm) |

*Sold Separately

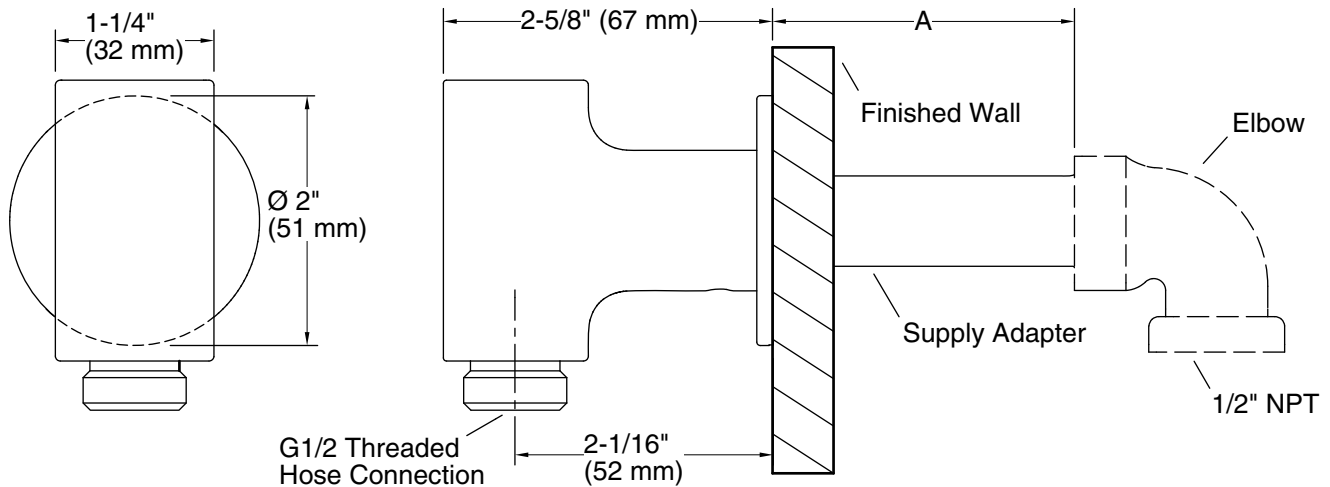

Technical Information

All product dimensions are nominal.

Drain included: No

Notes

Install this product according to the installation guide.

If dimension "A" is between 1-13/16" (46 mm) and 2-5/16" (59 mm) use the included supply adapter. For the other dimensions, order the appropriate supply adapter.