


## Kenzo™ Single Control Lavatory Faucet

- LG42-DFOB Finish(B)
- LG42-DFOC Finish(C)
- LG42-DFOK Finish(K)

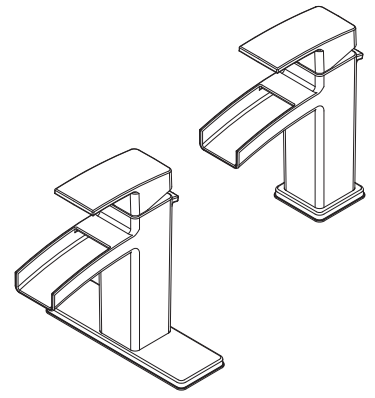

### Specifications

- Lever Handles
- 1 or 3-Hole Installation
- Pforever Seal

### Features

- 1.2 GPM Flow Rate
- All Metal Construction
- Complete Collection with Coordinating Roman Tub and Tub & Shower Options
- 1 or 3-Hole Installation; Deck Plate or Single Hole Mounting Option
- Single-Post Mounting Option
- Mounting Hardware Included
- Decorative Polished Trough Spout
- Metal Pop-Up
- Lever Handle
- Fixed Spout
- Pforever Seal Ceramic Disc Valve
- Pforever Warranty®

### Code Compliance

Pfister products are designed and manufactured in compliance with the following standards and codes:

- IAPMO Certified
- CSA B125 Certified
- ASME A112.18.1
- NSF 61/9 Annex G (Low lead)
- Cal Green Compliant
- EPA WaterSense Certification 1.2 gpm, 4.5L/Min
- ADA Compliant-ANSI A117.1 (Lever handles only)



### Dimensions

