


Avalon™ Tub and Shower Trim

- | | |
|---|--|
| R89-1CBC Finish(C) <input type="checkbox"/> | LG89-7CBC Finish(C) <input type="checkbox"/> |
| R89-1CBK Finish(K) <input type="checkbox"/> | LG89-7CBK Finish(K) <input type="checkbox"/> |
| R89-1CBY Finish(Y) <input type="checkbox"/> | LG89-7CBY Finish(Y) <input type="checkbox"/> |
| | LG89-8CBC Finish(C) <input type="checkbox"/> |
| | LG89-8CBK Finish(K) <input type="checkbox"/> |
| | LG89-8CBY Finish(Y) <input type="checkbox"/> |

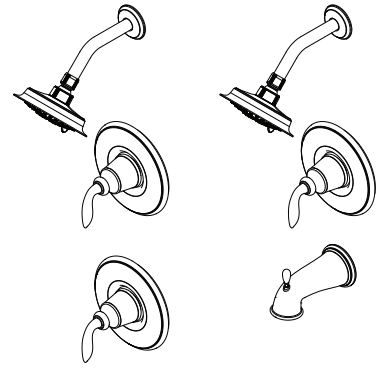

Specifications

- Trim Only, Valve Not Included

Features

- 1.8 GPM Flow Rate (Showerhead)
- SecurePfit™ Trim
- Easy To Clean Nozzles
- No Exposed Screws
- Requires OX8 or JX8 Valve Bodies
- Trim Only, Valve Not Included
- Flange Only (1CB Only)
- Shower Only (7CB Only)
- Tub & Shower (8CB Only)
- Quick Connect IP Tub Spout (8CB Only)
- 5 Function Showerhead (Full Spray, Massage, Combo, Rise, and Drench)
- Pforever Warranty®

Code Compliance

Pfister products are designed and manufactured in compliance with the following standards and codes:

- IAPMO Certified
- CSA B125 Certified
- ASME A112.18.1
- Cal Green Compliant
- CEC Compliant
- ADA Compliant-ANSI A117.1 (Lever handles only)
- EPA WaterSense Certification 1.8 gpm, 6.8L/Min



Dimensions

