


**DC POWER SUPPLY: 120 VAC TO 24 VDC**

**PSH24DWB10**

Enclosed Single Switching DC Power Supply 120 to 24 Vdc @ 2.5 Amp

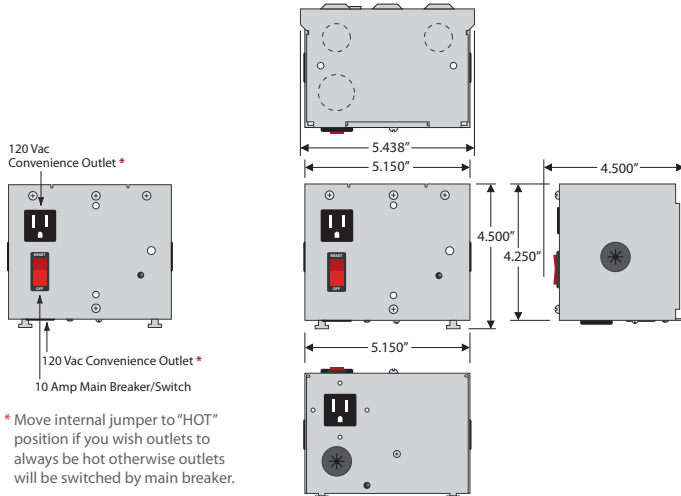

\* Move internal jumper to "HOT" position if you wish outlets to always be hot otherwise outlets will be switched by main breaker.



**SPECIFICATIONS**

**Input Voltage:** 120 Vac  
**Frequency:** 50/60 Hz  
**DC Output:** 24 Vdc @ 2.5 Amp

**Over Current Protection:** Circuit Breaker  
**Main Breaker ON/OFF:** Switch / Breaker (10 Amp)  
 (Kills power to entire unit)\*  
 Total Combined Output 9A

**Operating Temperature:** 32 to 122°F  
**Dimensions:** 4.500" x 5.438" x 4.500"

**Input Wires:** Input Power Wires  
 BLK: 120 Vac  
 WHT: Neutral  
 GRN: Ground

**Output Wires:** DC Supply Output  
 WHT/RED: 24 Vdc  
 WHT/BLU: 24 Vdc COM

Auxiliary Output  
 BLU: 120 Vac

**Notes:**  
 • This device is not certified for use as a Class 2 power source.