
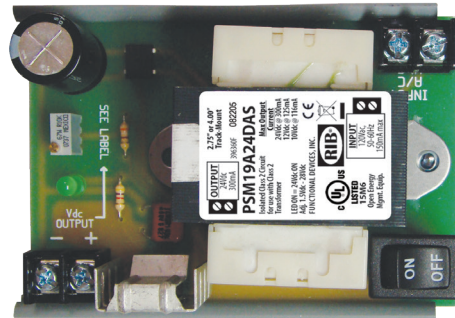


**DC POWER SUPPLY: 120 VAC TO 1.5 - 28 VDC**

**PSM19A24DAS**

4.00" & 2.75" Track Mount Isolated Linear DC Power Supply, 120 Vac to 1.5-28 Vdc, 300 mA Adjustable Output

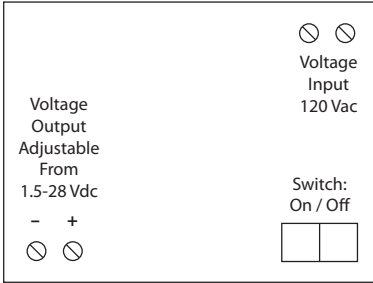

**SPECIFICATIONS**

- Voltage Input:** 120 Vac
- Voltage Output:** 1.5 - 28 Vdc Isolated
- Frequency:** 50/60 Hz
- Overload Protection:** Electrical and Thermal, Auto-Reset
- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Power Status:** LED On = Activated
- Dimensions:** 1.625" x 2.750" x 4.000"
- Track Mount:** 4.000" and 2.750" MT212-4 Mounting Track Supplied
- ON/OFF Switch:** 2 Position
- Approvals:** UL916, C-UL, CE, RoHS

- Output Current Ratings:**
  - 116 mA @ 10 Vdc
  - 125 mA @ 12 Vdc
  - 300 mA @ 24 Vdc

- Input Current Rating:** 150 mA Maximum

- Percent Ripple:** 0.0016%, 24 Vdc @ 300 mA

- Regulation:**
  - Load: 0.04% No Load to Full Load
  - Line: 0.6250 mV/V