
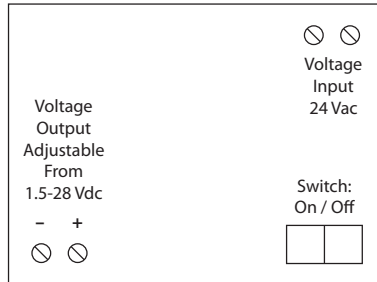


DC POWER SUPPLY: 24 VAC TO 1.5 - 28 VDC

PSM24A24DAS

4.00" & 2.75" Track Mount Isolated Linear DC Power Supply, 24 Vac to 1.5-28 Vdc, 300 mA Adjustable Output

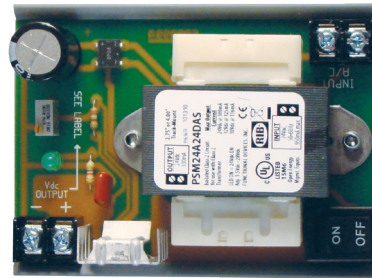

SPECIFICATIONS

Voltage Input: 24 Vac
Voltage Output: 1.5 - 28 Vdc Isolated
Frequency: 50/60 Hz
Overload Protection: Electrical and Thermal, Auto-Reset
Operating Temperature: -30 to 140° F
Humidity Range: 5 to 95% (noncondensing)
Power Status: LED On = Activated
Dimensions: 1.625" x 2.750" x 4.000"
Track Mount: 4.000" and 2.750" MT212-4 Mounting Track Supplied
ON/OFF Switch: 2 Position
Approvals: UL916, C-UL, CE, RoHS

Output Current Ratings:
 116 mA @ 10 Vdc
 125 mA @ 12 Vdc
 300 mA @ 24 Vdc

Input Current Rating:
 950 mA Maximum

Percent Ripple:
 0.0016%, 24 Vdc @ 300 mA

Regulation:
 Load: 0.04% No Load to Full Load
 Line: 0.0080 mV/V