


**AC POWER SUPPLY: 120 VAC TO 24 VAC**

**PSMN40AS**

2.75" Track Mount 40 VA Power Supply,  
120 Vac to 24 Vac, with Switch

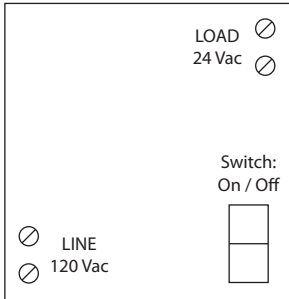

**SPECIFICATIONS**

- Transformers:** One 40 VA
- Primary:** 120 Vac
- Secondary:** 24 Vac, isolated
- Frequency:** 50/60 Hz
- Overload Protection:** Inherently limited
- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Power Status:** LED On = Secondary Voltage Present
- Dimensions:** 2.500" x 2.750" x 4.000" (without track)  
2.800" x 2.750" x 4.000" (in track)
- Track Mount:** MT212-4 Mounting Track Supplied
- ON/OFF Switch:** 2 Position
- Approvals:** UL916, C-UL, CE, RoHS