
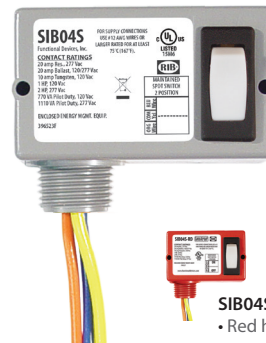


**PREPACKAGED SWITCH**

**SIB04S**

Enclosed Switch **20 Amp, 2 Position** Maintained, On/On, **3 Wires**

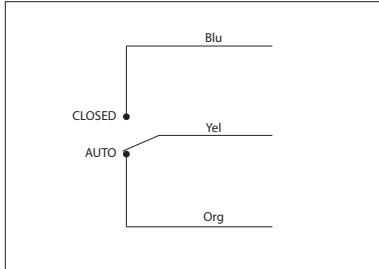

**SIB04S-RD**  
• Red housing



**SPECIFICATIONS**

**Operating Temperature:** -30 to 140° F  
**Humidity Range:** 5 to 95% (noncondensing)  
**Dimensions:** 1.700" x 2.800" x 1.500"  
 (w/ .500" NPT Nipple)  
**Wires:** 16", 600V Rated  
**Approvals:** UL Listed, UL916, C-UL, CE, RoHS  
**Housing Rating:** UL Accepted for Use in Plenum, NEMA 1

**Switch Ratings:**  
 20 Amp Resistive @ 277 Vac  
 1110 VA Pilot Duty @ 277 Vac  
 770 VA Pilot Duty @ 120 Vac  
 20 Amp Ballast @ 277 Vac  
 10 Amp Tungsten @ 120 Vac  
 2 HP @ 277 Vac  
 1 HP @ 120 Vac

**Notes:**  
 • Switch position label can be custom printed according to your needs, simply consult factory