 

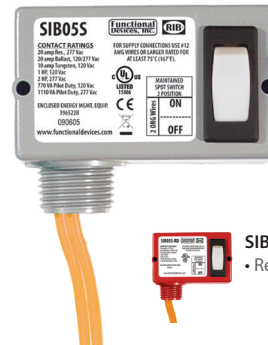


PREPACKAGED SWITCH

SIB05S

Enclosed Switch **20 Amp, 2 Position** Maintained, On/Off, **2 Wires**

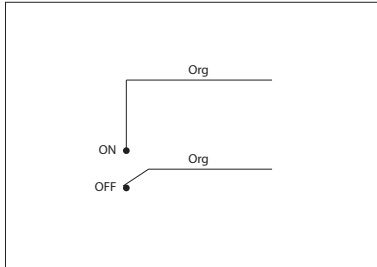

SPECIFICATIONS

Operating Temperature: -30 to 140° F
Humidity Range: 5 to 95% (noncondensing)
Dimensions: 1.700" x 2.800" x 1.500"
 (w/ .500" NPT Nipple)
Wires: 16", 600V Rated
Approvals: UL Listed, UL916, C-UL, CE, RoHS
Housing Rating: UL Accepted for Use in Plenum, NEMA 1

Switch Ratings:
 20 Amp Resistive @ 277 Vac
 1110 VA Pilot Duty @ 277 Vac
 770 VA Pilot Duty @ 120 Vac
 20 Amp Ballast @ 277 Vac
 10 Amp Tungsten @ 120 Vac
 2 HP @ 277 Vac
 1 HP @ 120 Vac

Notes:
 • Switch position label can be custom printed according to your needs, simply consult factory