
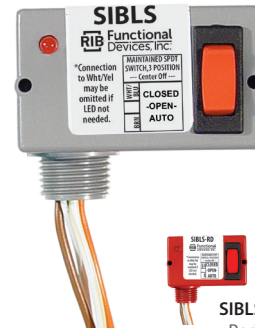


PREPACKAGED SWITCH

SIBLS

Enclosed Switch 5 Amp, 30 Vac/dc, 3 Position
Maintained, On/Off/On with LED Indicator

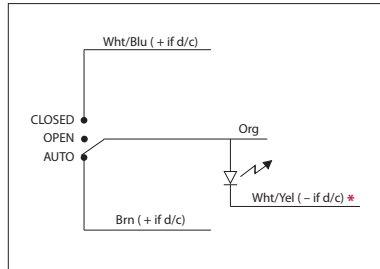

SIBLS-RD
• Red housing

SPECIFICATIONS

- Operating Temperature:** -30 to 140° F
- Humidity Range:** 5 to 95% (noncondensing)
- Dimensions:** 1.700" x 2.800" x 1.500"
(w/ .500" NPT Nipple)
- Wires:** 16", 600V Rated
- Approvals:** CE, RoHS
- Housing Rating:** UL Accepted for Use in Plenum, NEMA 1
- Switch Rating:** 5 Amp @ 30Vac/dc

- Notes:**
- Switch position label can be custom printed according to your needs, simply consult factory
 - Connection to Wht/Yel may be omitted if LED is not needed *