



www.velcro.com · AMAZING CONNECTIONS® ...

**VELCRO**<sup>®</sup>  
BRAND



## HEAVY DUTY




 **VELCRO**<sup>®</sup>



# HEAVY DUTY

Our Heavy Duty tapes, coins and strips are the ideal options for keeping things organized and connected. Ideal for tools, equipment, wall hangings and projects that require a little extra strength.

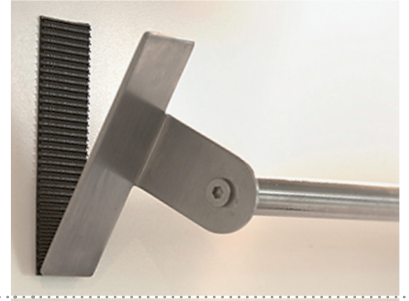

**VELCRO® Brand Industrial Strength** tapes, coins, and strips offer significantly more holding power than everyday VELCRO® Brand Sticky Back fasteners. They feature a molded plastic hook and a heavy duty, water-resistant adhesive for superior holding power on smooth surfaces including plastic.

### Available Colors



### Available Shapes



### Packaging Types



- Water resistant adhesive
- More holding power
- Adheres to most surfaces including plastic

**VELCRO® Brand ALFA-LOK™** fasteners feature new technology with superior holding power. Designed to adhere to most surfaces including vinyl and concrete.

### Available Colors



### Available Shapes



### Packaging Types



- Water & UV resistant adhesive
- Indoor/outdoor Use
- Superior Hold
- Designed for extreme temps ranging from -40° F to 194° F (-40° C to 90° C)

### Icon Descriptions



Please refer to the product table for detailed packaging information.

**VELCRO® Brand Industrial Strength - Low Profile** fasteners provide superior strength with 30% less thickness than our regular Industrial Strength products. These water-resistant, low profile hook and loop fasteners are ideal for smooth surfaces such as painted wallboard, glass, metal, and most plastics.

**Available Colors**



**Available Shapes**



**Packaging Types**



- Water resistant adhesive
- Low profile
- Adheres to most surfaces including plastic

**VELCRO® Brand Extreme Outdoor** fasteners feature an all-weather, UV-resistant adhesive for rough surfaces including concrete and certain types of brick. Superior holding power meets the requirements of demanding indoor and outdoor applications without drilling, nails, screws or epoxy.

**Available Colors**



**Available Shapes**



**Packaging Types**



- Professional grade adhesive
- Indoor/outdoor use
- UV resistant
- Designed to adhere to rough surfaces

**VELCRO® Brand Sticky Back for Auto** features vinyl-compatible adhesive specially formulated for use on dashboards and consoles. Excellent holding power for general uses in automobiles, RVs and boats.

**Available Colors**



**Available Shapes**



**Packaging Types**



- Professional grade adhesive
- Easy to use
- Designed to adhere to flexible vinyl

## HEAVY DUTY - Product Specifications

| Part #   | Description                          | Inner/<br>Master |
|--|--------------------------------------|------------------|
| <b>VELCRO® BRAND INDUSTRIAL STRENGTH</b>               |                                      |                  |
| 90197  | 15 Ft x 2 In Tape - Black            | 3/12             |
| 90198  | 15 Ft x 2 In Tape - White            | 3/12             |
| 90199  | 2 In x 4 In Strips, 2 Sets - Black   | 6/72             |
| 90200  | 2 In x 4 In Strips, 2 Sets - White   | 6/72             |
| 90362  | 1 7/8 In Coins, 4 Sets - Black       | 6/72             |
| 90363  | 1 7/8 In Coins, 4 Sets - White       | 6/72             |
| 90593  | 4 Ft x 2 In Tape - Black             | 2/18             |
| 90595  | 4 Ft x 2 In Tape - White             | 2/18             |
| 90943  | 10 Ft x 2 In Tape - Black            | 3/12             |
| 90944  | 10 Ft x 2 In Tape - White            | 3/12             |
| 91792  | 15 Ft x 2 In Tape, Flange - Black    | 12               |
| 91793  | 15 Ft x 2 In Tape, Flange - White    | 12               |
| VEL-30635-GLO  | 16.4 yd x 1 In Tape - Black          | 6                |
| VEL-30636-GLO  | 16.4 yd x 2 In Tape - Black          | 6                |
| VEL-30637-GLO  | 16.4 yd x 1 in Tape - White          | 6                |
| VEL-30638-GLO  | 16.4 yd x 2 in Tape - White          | 6                |
| <b>VELCRO® BRAND INDUSTRIAL STRENGTH - LOW PROFILE</b> |                                      |                  |
| 91000  | 1 In x 3/4 In Spots, 10 Sets - Black | 6/72             |
| 91010  | 1 In x 3/4 In Spots, 10 Sets - White | 6/72             |
| 91050  | 3 Ft x 1 In Tape - Black             | 5/25             |
| 91100  | 10 Ft x 1 In Tape - Black            | 3/12             |
| 91110  | 10 Ft x 1 In Tape - White            | 3/12             |

| Part #                                    | Description                               | Inner/<br>Master |
|---|---|------------------|
| <b>VELCRO® BRAND EXTREME OUTDOOR</b>      |   |                  |
| 90800                                     | 4 In x 1 In Strips, 5 Sets - Titanium     | 6/72             |
| 90812                                     | 4 In x 1 In Strips, 10 Sets - Titanium    | 3/36             |
| 91365                                     | 10 Ft x 1 In Tape - Titanium              | 3/12             |
| 91373                                     | 4 in x 2 In Strips, 2 Sets - Titanium     | 6/72             |
| 91839                                     | 4 in x 2 In Strips, 2 Sets - Black        | 6/72             |
| 91843                                     | 10 Ft x 1 In Tape - Black                 | 3/12             |
| <b>VELCRO® BRAND STICKY BACK FOR AUTO</b> |   |                  |
| 90850                                     | 3 1/2 In x 1 1/2 In Strips, 2 ct. - Black | 6/72             |
| 90879                                     | 3 1/2 In x 1 1/2 In Strips, 2 ct. - Gray  | 6/72             |
| 90881                                     | 2 Ft x 1 1/2 In Tape - Black              | 4/36             |
| 90884                                     | 2 Ft x 1 1/2 In Tape - Gray               | 4/36             |
| <b>VELCRO® BRAND ALFA LOK™</b>            |   |                  |
| VEL-30642-USA                             | ALFA-LOK™ 3in x 1in strips. 2 ct. black   | 6/24             |
| VEL-30643-USA                             | ALFA-LOK™ 3in x 1in strips. 4 ct. black   | 6/24             |

## AMERICAS

### USA

Velcro USA Inc.  
Tel: (+800) 225 0180

### Canada

Velcro Canada Inc.  
Tel: (+800) 683 5276

### Mexico

Velcro de Mexico, S.A. de C.V.  
Tel: (+52) 55 5005 3300

### Brasil

Velcro Brasil  
São Paulo  
Tel: (+55) 11 3651 8989  
São Luís  
Tel: (+55) 51 3599 2099



- Sales offices
- Manufacturing facilities
- Research & Development centres

## EMEA

### France

Velcro Industries France S.A.S.  
Tel: (+33) 0 1 34 38 78 88

### Germany

Velcro GmbH.  
Tel: (+49) 7141 991 19-0

### Italy

Velcro Italia, S.R.L.  
Tel: (+39) 039 62 70 01

### Spain

Velcro Europe S.A.  
Tel: (+34) 93 758 32 98

### UK

Velcro Limited.  
Tel: (+44) 1606 73 88 06

## APAC

### Australia

Velcro Australia Pty, Ltd.  
Tel: (+61) 3 9703 2466

### China

Velcro China Fastening  
Systems Company Limited.  
Tel: (+86) 21 6045 2090  
(Shanghai Sales Office)

### Hong Kong

Velcro Hong Kong Ltd.  
Tel: (+852) 2570 3698

[www.velcro.com](http://www.velcro.com) · (800) 235-6640



## VELCRO® BRAND FASTENER CATEGORIES



GENERAL PURPOSE



HEAVY DUTY



TIES AND STRAPS



FOR FABRICS



GARDEN